



- Fitting elements
- Flat cable clamp with single or dual bolts
- Material:
Clamp: Stainless steel 316 plated steel Fe360B

Info.

- Not sold individually, please contact us for details

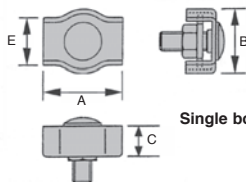

Single bolt

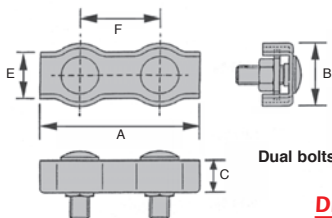

Dual bolts

DISCOUNTS

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Ø Cable	A	B	C	E	F	Weight per 100 pieces (kg)	Stock*	Price each 1 to 29
Single bolts									
SCA1-02/SS	2	15	11	5,0	7	-	0,438	✓	1,19 €
SCA1-03/SS	3	17	14	6,0	9	-	0,520	✓	1,52 €
SCA1-04/SS	4	20	17	7,0	11	-	1,090	✓	1,87 €
SCA1-05/SS	5	25	19	8,5	13	-	1,442	✓	2,52 €
SCA1-06/SS	6	30	24	10,0	16	-	2,630	✓	4,09 €
Dual bolts									
SCA2-02/SS	2	30	11	5,0	7	15	0,926	✓	1,95 €
SCA2-03/SS	3	34	14	6,0	9	17	1,230	✓	2,59 €
SCA2-04/SS	4	40	17	7,0	11	19	2,290	✓	3,53 €
SCA2-05/SS	5	50	19	8,5	13	25	3,090	✓	4,48 €
SCA2-06/SS	6	60	24	10,0	16	30	5,440	✓	6,28 €

*Depending on availability - Dimensions in mm

Our other products



PSG2

Spur gear - precision range, Pre-hardened Steel 35NCD6



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2 directions



LVT

Miniature motorised actuator 1A, 1 amper



LOQ

Manual lock, Manual latch



GCT

Pipe linch pin, Tube linch pin



B_ECO

Eco. range steel bevel gear, 1:1



F7-E

Multifunction display, With external sensor



 
EMS

Stainless steel knurled thumb nut, Knurled



ACLERP

Roller block for aluminium profile,



CHB

Worm and wheel gear reducer, up to 41 Nm



PRF_CHA

Hinge for aluminium profile, Surface



SH0

 
Parallel axis helical gear, Steel 20NCD2

Complementary products



SCA_SS

Stainless steel flat cable clamp, Stainless steel



CAB

Stainless steel cable, Stainless steel



CCLSS

Stainless steel wire thimble, Stainless steel



PPCss

Pad eye on mounting plate squarred, Stainless steel