

Flat cable clamp






SCA

Suitable for cable Ø2-Ø6mm

- Fitting elements
- Flat cable clamp with single or dual bolts
- Material:
Clamp: Zinc plated steel Fe360B

Info.

- Not sold individually, please contact us for details

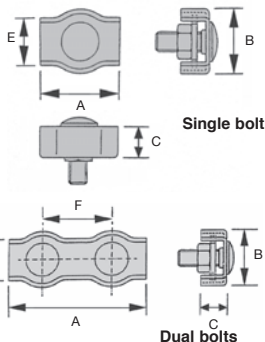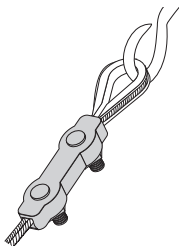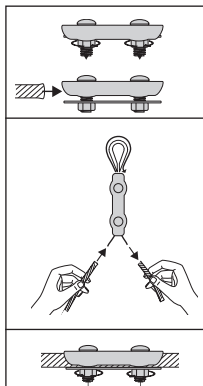

DISCOUNTS

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Ø Cable	A	B	C	E	F	Weight per 100 pieces (kg)	Stock*	Price each 1 to 29
Single bolts									
SCA1-02	2	18	12	5	8	-	0,50	✓	0,42 €
SCA1-03	3	20	14	7	10	-	0,75	✓	0,58 €
SCA1-04	4	22	17	8	12	-	1,15	✓	0,66 €
SCA1-05	5	26	21	9	14	-	2,00	✓	0,80 €
SCA1-06	6	30	25	10	17	-	3,00	✓	0,87 €
Dual bolts									
SCA2-02	2	37	13	5	8	20	1,10	✓	0,72 €
SCA2-03	3	40	15	7	10	21	1,50	✓	0,80 €
SCA2-04	4	43	17	7	13	22	2,50	✓	0,91 €
SCA2-05	5	52	22	9	15	27	4,00	✓	1,44 €
SCA2-06	6	60	26	9	18	33	6,00	✓	1,65 €

*Depending on availability - Dimensions in mm

Our other products



CSSSS
Stainless steel
spherical bearing,
Stainless steel / PTFE



CHAPAM
Weld-on hinge with
flat end, Steel



CHAR16046
Spring hinge, screwed



GP
Spring loaded toggle
latch, With padlock-
holder




PRRS100
Stainless steel
articulated foot Ø100,
Ø 100



CM
Tools Hygienic Usit®
and Hygienic
Design®,
Combination spanner



 CHM30
Worm and wheel gear
reducer, up to 28 Nm



PM2
Worm and wheel set,
Machined plastic
(delrin)



RURp
Fixed castor with
plate, Polyurethane -



PM4
Worm and wheel set,
Machined plastic

 


PRF_GAL
Roller for aluminium
profile, Flat roller



BAGtr
Lead screw clamping
collar, Aluminium

Complementary products



CAB
Galvanised steel
cable, Galvanised
steel



SCA
Flat cable clamp,
Steel



CCL
Standard wire
thimble, Steel