



- Fitting elements
- Flat cable clamp with single or dual bolts
- Material:  
Clamp: Stainless steel 316 plated steel Fe360B

**Info.**

- Not sold individually, please contact us for details

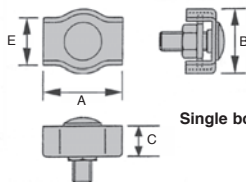

Single bolt

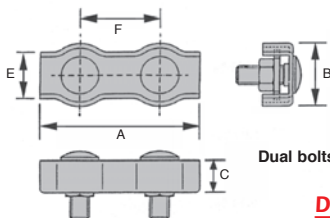

Dual bolts

**DISCOUNTS**

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Ø Cable	A	B	C	E	F	Weight per 100 pieces (kg)	Stock*	Price each 1 to 29
<b>Single bolts</b>									
SCA1-02/SS	2	15	11	5,0	7	-	0,438	✓	1,19 €
SCA1-03/SS	3	17	14	6,0	9	-	0,520	✓	1,52 €
SCA1-04/SS	4	20	17	7,0	11	-	1,090	✓	1,87 €
SCA1-05/SS	5	25	19	8,5	13	-	1,442	✓	2,52 €
SCA1-06/SS	6	30	24	10,0	16	-	2,630	✓	4,09 €
<b>Dual bolts</b>									
SCA2-02/SS	2	30	11	5,0	7	15	0,926	✓	1,95 €
SCA2-03/SS	3	34	14	6,0	9	17	1,230	✓	2,59 €
SCA2-04/SS	4	40	17	7,0	11	19	2,290	✓	3,53 €
SCA2-05/SS	5	50	19	8,5	13	25	3,090	✓	4,48 €
SCA2-06/SS	6	60	24	10,0	16	30	5,440	✓	6,28 €

\*Depending on availability - Dimensions in mm

## Our other products




AT5-10ECO

AT type timing pulley,  
Economy range - AT5  
aluminium



VELprf

 Clip-on base for hook-  
and-loop strip,  
Polyamide



RPPM

RPP type belt per  
metre, RPP8 Steel  
cored polyurethane



TBD

Manual leadscrew  
table with opposing  
threads, 2kg



PF45

Worm and wheel gear  
reducer, up to 40 Nm



MHPGR

Arm with folding  
rotating handle,



PW\_PWG2

Wheel - precision  
range, Bronze



BH01

Single housed  
bearing, Bearing fitted  
with adhesive



BOX-TOR-A

Box set of Nitrile O-  
rings in nitrile, 2.90 x



NKX

Combined bearing  
without inner ring,



PW\_PWG3

Worm - precision  
range, Steel



NDS20


Double cross clamp,  
Crossed

## Complementary products



 SCA\_SS

Stainless steel flat  
cable clamp, Stainless  
steel



CAB

Stainless steel cable,  
Stainless steel



PPRss

Pad eye on mounting  
plate round, Stainless  
steel



CCLSS

Stainless steel wire  
thimble, Stainless  
steel