

U-shaped cable clamp

Stock Ste ★★★

SCE

Suitable for cable Ø5-Ø16mm



- Hot stamped clamp for steel cable or rope
- Fitting components
- Material:
 - U bolt: zinc plated steel Fe360B
 - Plate: zinc plated steel Fe430B

Assembly

- For cables Ø5 to Ø12, use 4 cable clamps
- For cables Ø12 to Ø16, use 5 cable clamps

Info.

- Not sold individually, please contact us for details

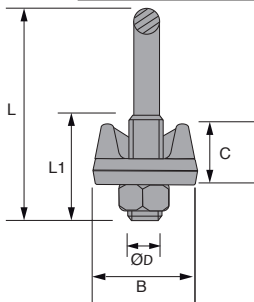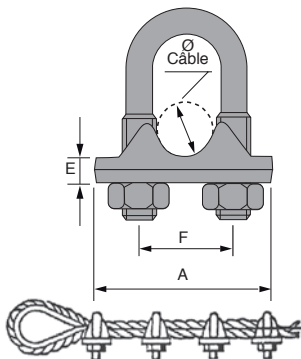

The attached end of the cable should be placed next to the plate, the free end next to the curve of the U

DISCOUNTS

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Int Ø	Ø	A	B	C	ØD	E	F	L	L1	Weight/ 100 pieces (kg)	Stock*	Price each 1 to 29
SCE1-05	5	5	25	18	9	M5	5	10	27	16	2,40	✓	0,87 €
SCE1-06	6	6	30	19	10	M6	6	14	33	19	3,90	✓	0,91 €
SCE1-08	8	8	33	20	11	M6	7	16	34	19	4,40	✓	1,11 €
SCE1-10	10	10	38	22	12	M8	7	20	44	22	7,50	✓	1,52 €
SCE1-12	12	12	43	25	14	M10	7	23	56	30	12,70	✓	1,99 €
SCE1-14	14	14	46	28	16	M10	9	27	56	30	15,50	✓	2,29 €
SCE1-16	16	16	53	31	18	M10	8	29	65	30	19,50	-	2,90 €

*Depending on availability - Dimensions in mm

Our other products



CHB

Worm and wheel gear reducer, up to 41 Nm



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



BOX-CS

Hose clamp, Box set of steel hose clamps



CHALss

Piano hinge, Stainless steel



ZBconique

Machined plastic bevel gear, 1:1



PW_PWG1

Worm - precision range, Steel



PSG125

Spur gear - precision range, Case hardened steel 20NCD2



M1

Worm and wheel set, Hardened steel



ZBconique

Machined plastic bevel gear, 1:1



RHT

High Temperature wheel, up to 200kg



LVT

 
Miniature motorised actuator 1A, 1 ampere



H02SS

Needle roller universal joint - Stainless steel, Heavy duty DIN808-7...

Complementary products



CAB

Galvanised steel cable, Galvanised steel



CCL

Standard wire thimble, Steel