

U-shaped cable clamp

Stock Ste ★★★

SCE

Suitable for cable Ø5-Ø16mm



- Hot stamped clamp for steel cable or rope
- Fitting components
- Material:
 - U bolt: zinc plated steel Fe360B
 - Plate: zinc plated steel Fe430B

Assembly

- For cables Ø5 to Ø12, use 4 cable clamps
- For cables Ø12 to Ø16, use 5 cable clamps

Info.

- Not sold individually, please contact us for details

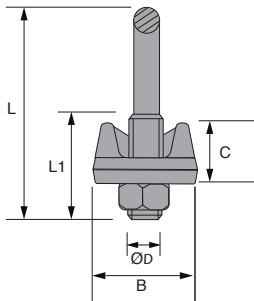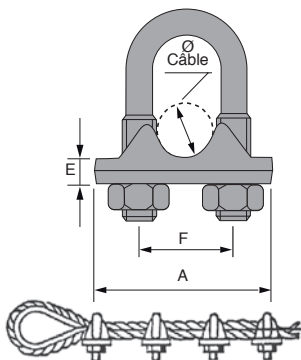

The attached end of the cable should be placed next to the plate, the free end next to the curve of the U

DISCOUNTS

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Int Ø	Ø	A	B	C	ØD	E	F	L	L1	Weight/ 100 pieces (kg)	Stock*	Price each 1 to 29
SCE1-05	5	5	25	18	9	M5	5	10	27	16	2,40	✓	0,87 €
SCE1-06	6	6	30	19	10	M6	6	14	33	19	3,90	✓	0,91 €
SCE1-08	8	8	33	20	11	M6	7	16	34	19	4,40	✓	1,11 €
SCE1-10	10	10	38	22	12	M8	7	20	44	22	7,50	✓	1,52 €
SCE1-12	12	12	43	25	14	M10	7	23	56	30	12,70	✓	1,99 €
SCE1-14	14	14	46	28	16	M10	9	27	56	30	15,50	✓	2,29 €
SCE1-16	16	16	53	31	18	M10	8	29	65	30	19,50	-	2,90 €

*Depending on availability - Dimensions in mm

Our other products



SHA
Handwheel without handle, Polyamide



TS01_TW01
Drylin® T linear slide, up to 7000 N



STC
Shock Absorber - stop collar, Universal flange



PCS62SS
Chain sprocket - Stainless steel, 15.875mm (DIN 08B-1)



GBSz
Cylindrical ballscrew nut, Cylindrical leadscrew nut



LRR
Spring loaded latch, Spring loaded latch



SERB
Universal latch key, Universal latch key




PLA
Flat magnet, Flat magnet with thread



PTA50
Articulated levelling foot, pressed base Ø50, Ø 50



 SBF
Sealed flange bearing unit for Food Industry, cover



PRT
Rotary table iglidur®, iglidur®, aluminium and stainless steel

 


RBGpl
Swivel castor with plate, Steel - grey rubber

Complementary products



SCE_SS
Stainless steel U-shaped clamp, Stainless steel



CAB
Galvanised steel cable, Galvanised steel



CCL
Standard wire thimble, Steel