

- Clamp for steel cable or rope
- Fitting components
- Material:
U bolt + plate: stainless steel



Assembly

- For cables Ø5 to Ø12, use 4 cable clamps
- For cables Ø12 to Ø16, use 5 cable clamps

Info.

- Not sold individually, please contact us for details

stainless steel

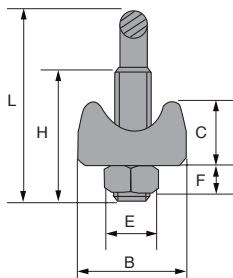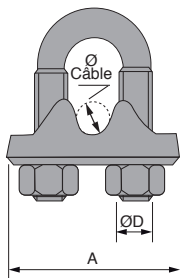

The attached end of the cable should be placed next to the plate, the free end next to the curve of the U

DISCOUNTS

Qty	1+	30+	60+	90+	120+	150+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Ø Cable	A	B	C	ØD	E	F	L	L1	Weight per 100 pieces (kg)	Stock*	Price each
												1 to 29
SCE1-05/SS	5	25	18	9	M5	8	5	15	26	2,40	✓	2,62 €
SCE1-06/SS	6	30	19	10	M6	10	5	20	33	3,80	✓	3,51 €
SCE1-08/SS	8	33	20	10	M6	10	5	23	35	4,50	✓	3,67 €
SCE1-10/SS	10	38	22	12	M8	13	6	24	43	7,50	✓	5,71 €
SCE1-12/SS	12	45	25	16	M10	17	8	30	54	13,08	-	9,84 €
SCE1-14/SS	14	46	27	17	M10	17	8	31	56	16,00	-	11,32 €
SCE1-16/SS	16	52	31	17	M9	17	9	31	65	20,00	-	14,54 €

*Depending on availability - Dimensions in mm

Our other products



KBS_UU

Stainless steel closed precision linear bearing, Precision - stainless steel...



LWL

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



SCE

U-shaped cable clamp, Steel



PSG05HC

Skive hobbled spur gears - precision range, Case hardened steel 20NCD2



LVT

Miniature motorised actuator 1A, 1 amper



UCFL_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



RFVfp

Stainless steel worm and wheel gearboxes, Mounting bracket



FUSS

Bearing locknut, Self locking locknut -



WINGbr

Wing screw, hand tightened DIN316,



UTKswc

 
Utilitrac® 3 wheels carriage, Series V



T5P_T10P

Connecting plate for T type timing belts, T5

Complementary products



CAB

Stainless steel cable, Stainless steel



CCLSS

Stainless steel wire thimble, Stainless steel



PPOss

Pad eye on mounting plate oval, Stainless steel



CABPVC

PVC covered galvanised steel cable, Galvanised steel with

