

- **Two materials to choose from**
- **Materials:**
SLV body: zinc plated steel
SCH/SS body: stainless steel 18.9 (303)
Rivets: stainless steel
Fastening pin and nuts: phosphated steel
Handle: oil-resistant plastic
- **With fixing base and adjustable fastening pin**

steel or stainless steel




Advantages

- **The angle between retaining arm to the handle can be adjusted by removing the gudgeon**

Options

- **Mounting bracket (please ask us)**

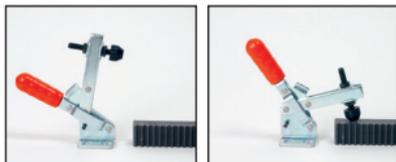


Typical application

| Part number | | Opening angle of retaining arm | | | Opening angle of handle | | | A1 | B1 | H |
|-------------|-----------------|--------------------------------|-------|-----------------|-------------------------|-------|-----------------|----|----|-----|
| Steel | Stainless steel | Pos.1 | Pos.2 | without gudgeon | Pos.1 | Pos.2 | without gudgeon | | | |
| SLV-0075 | SLV-0075SS | 130° | - | 160° | 90° | - | 100° | 25 | 34 | 94 |
| SLV-0100 | - | 95° | - | 185° | 65° | - | 105° | 29 | 34 | 98 |
| SLV-0150 | SLV-0150SS | 95° | - | 185° | 75° | - | 110° | 27 | 38 | 121 |
| SLV-0200 | - | 105° | - | 175° | 70° | - | 95° | 35 | 42 | 135 |
| SLV-0250 | SLV-0250SS | 95° | 125° | 160° | 70° | 85° | 100° | 35 | 45 | 175 |
| SLV-0300 | - | 105° | - | 160° | 65° | - | 90° | 43 | 53 | 186 |
| SLV-0350 | - | 90° | 120° | 180° | 70° | 80° | 110° | 50 | 64 | 220 |
| SLV-0450 | - | 90° | 125° | 180° | 70° | 85° | 110° | 53 | 64 | 228 |
| SLV-0550 | - | 90° | 120° | 180° | 65° | 80° | 110° | 76 | 95 | 312 |

| Part number | | Manual force (N) | Holding force | | Locking force | | C | C1 | L1 |
|-------------|-----------------|------------------|---------------|-------|---------------|-------|----|------|-----|
| Steel | Stainless steel | (N) | F1(N) | F2(N) | F3(N) | F4(N) | | | |
| SLV-0075 | SLV-0075SS | 80 | 700 | 1100 | 500 | 750 | 16 | 9,0 | 32 |
| SLV-0100 | - | 80 | 700 | 1000 | 500 | 800 | 22 | 9,5 | 38 |
| SLV-0150 | SLV-0150SS | 120 | 1350 | 1650 | 800 | 1050 | 23 | 11,0 | 43 |
| SLV-0200 | - | 100 | 1000 | 2200 | 950 | 1350 | 30 | 12,7 | 44 |
| SLV-0250 | SLV-0250SS | 190 | 1000 | 2800 | 900 | 1700 | 32 | 17,5 | 75 |
| SLV-0300 | - | 130 | 2000 | 3700 | 900 | 1850 | 34 | 19,0 | 100 |
| SLV-0350 | - | 230 | 2200 | 4500 | 1400 | 3000 | 43 | 22,0 | 95 |
| SLV-0450 | - | 260 | 3200 | 7000 | 1400 | 3000 | 51 | 25,0 | 124 |
| SLV-0550 | - | 290 | 3000 | 8000 | 1800 | 3900 | 84 | 32,0 | 156 |

*Subject to availability - Dimensions in mm

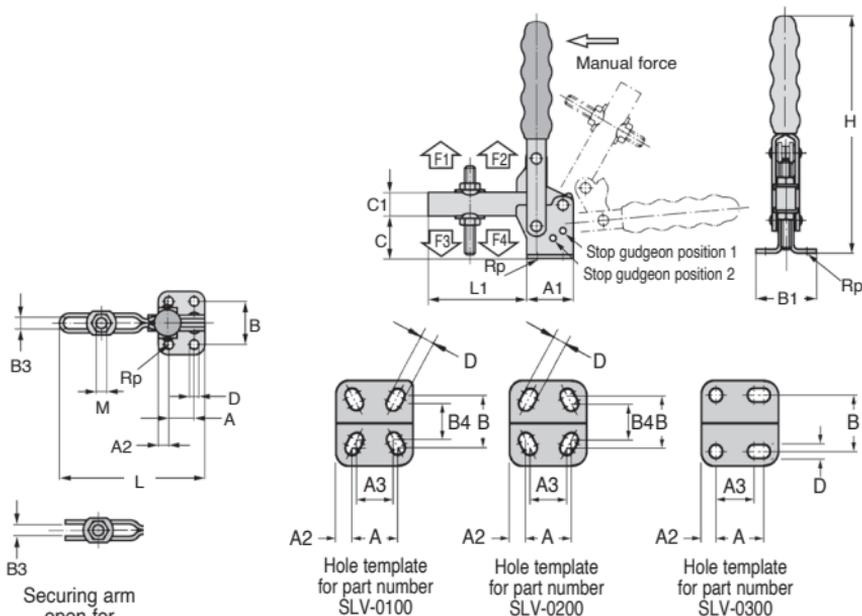

Securing arm open for SLV-0100, SLV-0200, and SLV-0300

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 15+ | 20+ |
| Disc. | List | -5% | -10% | On request |

| Part number | A | A2 | A3 | B | B3 | B4 | D | L | M | Stock* | Price each 1 to 5 |
|------------------------|------|------|------|------|------|------|------|-----|---------|--------|-------------------|
| Steel | | | | | | | | | | | |
| SLV-0075 | 16,0 | 5,0 | - | 24,0 | 5,5 | - | 4,4 | 57 | M5x35 | ✓ | 23,10 € |
| SLV-0100 | 16,0 | 6,0 | 14,0 | 24,0 | 5,5 | 17,5 | 4,8 | 67 | M5x35 | ✓ | 22,84 € |
| SLV-0150 | 12,7 | 7,0 | - | 27,0 | 6,4 | - | 5,1 | 70 | M6x50 | ✓ | 26,30 € |
| SLV-0200 | 19,0 | 8,0 | 12,7 | 27,0 | 6,3 | 25,0 | 5,5 | 79 | M6x50 | ✓ | 26,32 € |
| SLV-0250 | 19,0 | 8,0 | - | 32,0 | 8,8 | - | 7,1 | 110 | M8x60 | ✓ | 40,64 € |
| SLV-0300 | 25,0 | 9,0 | 19,0 | 34,5 | 8,8 | - | 8,0 | 143 | M8x60 | ✓ | 48,95 € |
| SLV-0350 | 32,0 | 9,0 | - | 45,0 | 10,6 | - | 8,3 | 145 | M10x80 | ✓ | 54,65 € |
| SLV-0450 | 32,0 | 10,0 | - | 45,0 | 12,7 | - | 8,7 | 177 | M12x100 | ✓ | 69,46 € |
| SLV-0550 | 51,0 | 12,5 | - | 70,0 | 16,5 | - | 12,3 | 232 | M16x150 | - | 93,19 € |
| Stainless steel | | | | | | | | | | | |
| SLV-0075SS | 16,0 | 5,0 | - | 24,0 | 5,5 | - | 4,4 | 57 | M5x35 | ✓ | 58,46 € |
| SLV-0150SS | 12,7 | 7,0 | - | 27,0 | 6,4 | - | 5,1 | 70 | M6x50 | ✓ | 75,14 € |
| SLV-0250SS | 19,0 | 8,0 | - | 32,0 | 8,8 | - | 7,1 | 110 | M8x60 | ✓ | 105,12 € |

*Subject to availability - Dimensions in mm

Horizontal toggle clamp




SLH

Secures by direct pressure

- Materials:
 Body: zinc plated steel
 Fastening pin and nuts: phosphated steel
 Handle: Oil resistant plastic
- With fixing base and adjustable fastening pin

Options

- Mounting bracket (please ask us)

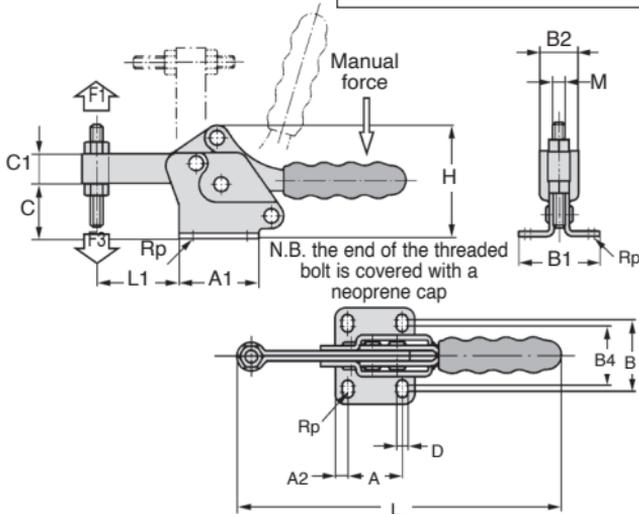

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty. | 1+ | 6+ | 15+ | 20+ |
| Disc. | List | -5% | -10% | On request |

| Part number | Opening angle of securing arm Pos. 1 | Opening angle of handle Pos. 1 | Manual force (N) | Manual force F1(N) | Securing force F3(N) |
|-------------|--------------------------------------|--------------------------------|------------------|--------------------|----------------------|
| SLH-0075 | 90° | 75° | 80 | 750 | 320 |
| SLH-0150 | 90° | 80° | 140 | 1500 | 650 |

| Part number | A | A1 | A2 | B | B1 | B2 | B4 | C | C1 | D | H | L | L1 | M | Stock* | Price each 1 to 5 |
|-------------|------|----|-----|------|----|----|----|----|------|-----|----|-----|------|-------|--------|-------------------|
| SLH-0075 | 13,5 | 25 | 5,7 | 16,8 | 27 | 16 | - | 19 | 9,5 | 5,2 | 38 | 108 | 24,5 | M5x35 | ✓ | 26,30 € |
| SLH-0150 | 26,0 | 38 | 6,0 | 28,0 | 40 | 20 | 22 | 25 | 14,0 | 5,5 | 53 | 155 | 38,0 | M6x50 | ✓ | 31,01 € |

*Depending on availability - Dimensions in mm

- 2 materials to choose from

- Materials:

SCH body: zinc plated steel

SCH/SS body: stainless steel 18.9 (303)

Handle: Oil-resistant plastic

- Supplied with anchoring base

Advantages


- Distance of hook from toggle clamp easily adjustable

Uses

- Designed to secure covers and shutters



Steel or stainless steel

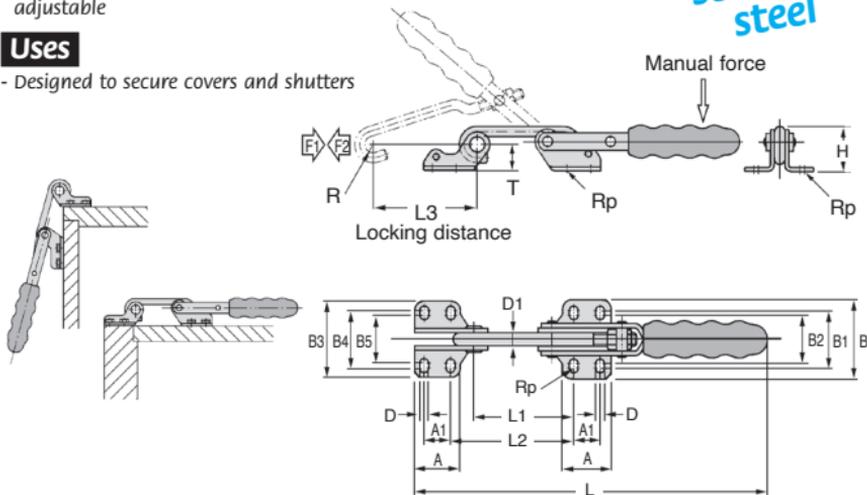

DISCOUNTS

| Qty | 1+ | 6+ | 15+ | 20+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Size | Traction force F1 (N) | Pressure F2 (N) | Manual force (N) | Handle opening angle | L | L1 | L2 | Locking distance L3 | A | A1 |
|--------|-----------------------|-----------------|------------------|----------------------|-----|----|-----|---------------------|----|----|
| SCH-01 | 1500 | 2000 | 100 | 155° | 161 | 45 | 58 | 70 | 26 | 13 |
| SCH-02 | 3000 | 4000 | 160 | 155° | 248 | 68 | 84 | 90 | 35 | 19 |
| SCH-04 | 4000 | 7000 | 200 | 155° | 310 | 84 | 104 | 115 | 51 | 32 |

| Part number | | | | | | | | | | | | Stock* | | Price each 1 to 5 | | |
|-------------|-----------------|----|------|------|----|----|----|-----|----|----|----|--------|-------|-------------------|----------|----------|
| Steel | Stainless steel | B | B1 | B2 | B3 | B4 | B5 | D | D1 | H | R | T | Steel | StS | Steel | StS |
| SCH-0130 | SCH-0130SS | 39 | 27,0 | 22,2 | 43 | 31 | 26 | 5,2 | 6 | 26 | 6 | 13,5 | ✓ | ✓ | 56,66 € | 66,07 € |
| SCH-0270 | SCH-0270SS | 52 | 36,0 | 29,0 | 57 | 41 | 34 | 6,5 | 8 | 35 | 7 | 20,0 | ✓ | ✓ | 83,73 € | 99,85 € |
| SCH-0430 | SCH-0430SS | 72 | 52,5 | 43,5 | 78 | 59 | 50 | 8,5 | 12 | 49 | 10 | 27,0 | - | - | 106,05 € | 208,47 € |

*Depending on availability - Dimensions in mm

- 2 materials to choose from

- Materials:

SEV body: zinc plated steel

SEV/SS body: stainless steel 18.9 (303)

Handle: Oil-resistant plastic

- Supplied with anchoring base


Advantages

- Distance of hook from toggle clamp easily adjustable

Uses

- Designed to secure covers and shutters

Steel or stainless steel

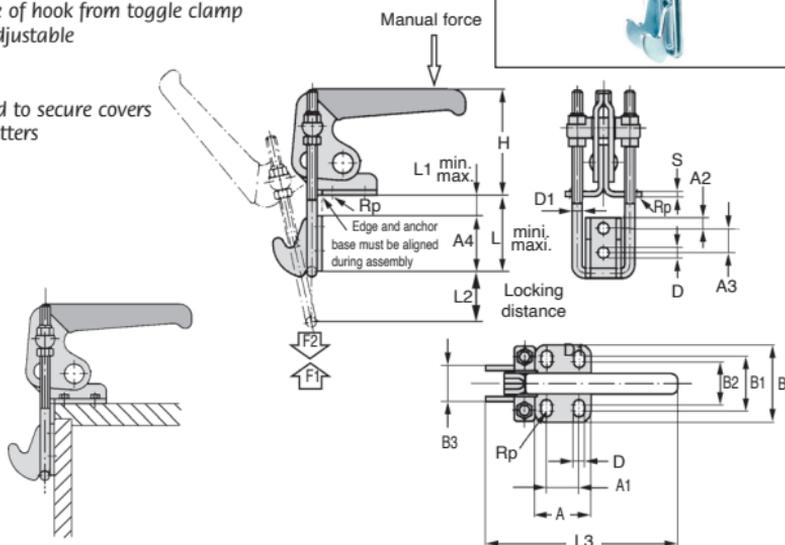

DISCOUNTS

| Qty | 1+ | 6+ | 15+ | 20+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Size | Traction force F1(N) | Pressure F2(N) | Manual force (N) | Opening angle of handle | Adjustable distance L1 | | Locking distance L2 L3 | |
|--------|-------------------------|-------------------|---------------------|----------------------------|---------------------------|------|---------------------------|-----------|
| | | | | | Min. | Max. | Min. | Max. |
| SEV-01 | 1800 | 2000 | 100 | 145° | 25 | 49 | 1 | 25 22 76 |
| SEV-02 | 2700 | 4000 | 150 | 145° | 33 | 60 | 1 | 28 34 115 |
| SEV-04 | 4500 | 7000 | 200 | 145° | 41 | 80 | 1 | 40 45 152 |

| Part number | | | | | | | | | | | | Price each 1 to 5 | | | | |
|-------------|-----------------|----|----|-----|----|----|----|----|----|----|-----|----------------------|----|-----|--------|----------|
| Steel | Stainless steel | A | A1 | A2 | A3 | A4 | B | B1 | B2 | B3 | D | D1 | H | S | Steel | StS |
| SEV-0140 | SEV-0140SS | 26 | 13 | 4,5 | 11 | 24 | 36 | 24 | 19 | 16 | 5,2 | 4 | 42 | 2,5 | 52,74 | € 68,27 |
| SEV-0250 | SEV-0250SS | 35 | 19 | 6,0 | 14 | 32 | 48 | 33 | 26 | 21 | 6,5 | 6 | 64 | 3,0 | 77,93 | € 96,04 |
| SEV-0450 | SEV-0450SS | 51 | 32 | 8,0 | 19 | 40 | 64 | 45 | 36 | 28 | 8,5 | 8 | 85 | 4,0 | 130,58 | € 182,27 |

Dimensions in mm

- 2 materials to choose from

- Materials:

SEH body: zinc plated steel

SEH/SS body: stainless steel 18.9 (303)

Handle: Oil-resistant plastic



- Supplied with anchoring base

Advantages

- Distance of hook from toggle clamp easily adjustable

Uses

- Designed to secure covers and shutters

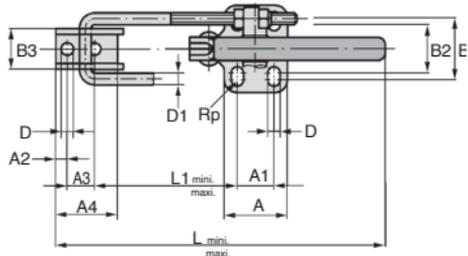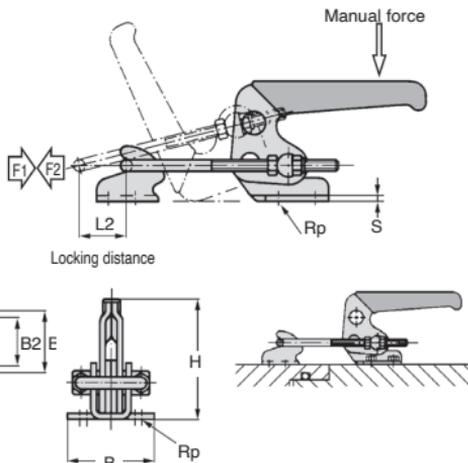

DISCOUNTS

| | | | | |
|------------|-----|------|------------|-----|
| Qty. | 1+ | 6+ | 15+ | 20+ |
| Disc. List | -5% | -10% | On request | |

| Size | Traction force F1(N) | Pressure force F2(N) | Manual force (N) | Opening angle | B | B1 | B2 | H | Adjustable distance L | | L1 | | Locking distance L2 |
|--------|-------------------------|-------------------------|---------------------|---------------|----|----|----|----|--------------------------|------|------|------|------------------------|
| | | | | | | | | | min. | max. | min. | max. | |
| SEH-01 | 1800 | 2000 | 100 | 120° | 36 | 24 | 19 | 42 | 105 | 135 | 38 | 68 | 16 |
| SEH-02 | 2700 | 4000 | 150 | 120° | 48 | 33 | 26 | 64 | 145 | 185 | 45 | 85 | 24 |
| SEH-04 | 4500 | 7000 | 200 | 120° | 64 | 45 | 36 | 85 | 190 | 250 | 65 | 120 | 32 |

| Part number | | | | | | | | | | | | | Price each 1 to 5 | |
|-------------|-----------------|----|----|-----|------|----|----|-----|----|-----|----------|----------|----------------------|--|
| Steel | Stainless steel | A | A1 | A2 | A3 | A4 | B3 | D | D1 | S | Steel | StS | | |
| SEH-0140 | SEH-0140SS | 26 | 13 | 4,5 | 11,0 | 23 | 16 | 5,2 | 4 | 2,5 | 52,74 € | 59,73 € | | |
| SEH-0250 | SEH-0250SS | 35 | 19 | 6,0 | 14,0 | 32 | 21 | 6,5 | 6 | 3,0 | 77,93 € | 89,47 € | | |
| SEH-0450 | SEH-0450SS | 51 | 32 | 8,0 | 19,0 | 40 | 28 | 8,5 | 8 | 4,0 | 130,58 € | 181,97 € | | |

Dimensions in mm

Horizontal toggle clamp

SLHHLOK

With locking mechanism

High quality swivel bush with horizontal foot and adjustable spindle

Constant level of force during both opening and closing

Increased stability thanks to U-shaped clamping arm
Fitted with automatic locking mechanism

- Materials :




Nitro carburised steel with blackened finish

Polyamide handle

Locking mechanism TPE



Horizontal base

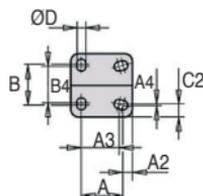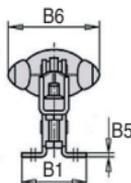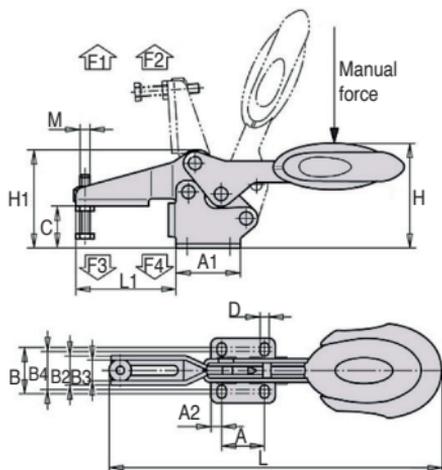

Hole positions

DISCOUNTS

| Qty | 1+ | 6+ | 15+ | 20+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | Opening angle | | Manual force N | Holding force | | | | Clamping force | | | |
|-------------|---------------|--------|-------------------|---------------|-----------|-----------|-----------|----------------|-------|-------|-------|
| | Holding arm | Handle | | F1 (N) | F2 (N) | F3 (N) | F4 (N) | H | H1 | L | L1 |
| SLHH-6/LOK | 87° | 68° | 160 | 1350 | 1900 | 720 | 1200 | 63,3 | 59,5 | 193,3 | 60,5 |
| SLHH-8/LOK | 86° | 66° | 200 | 2000 | 2800 | 830 | 1400 | 73,9 | 70 | 230,3 | 74,9 |
| SLHH-10/LOK | 90° | 71° | 250 | 2200 | 4500 | 1200 | 2800 | 94,8 | 87,9 | 286 | 103,9 |
| SLHH-12/LOK | 88° | 68° | 280 | 2400 | 5500 | 1000 | 2800 | 104,9 | 101,6 | 321,3 | 122 |

| Part number | M | A | A1 | A2 | A3 | A4 | B | B1 | B2 | B3 | B4 | B5 | B6 | C | C2 | ØD | Price each |
|-------------|--------|------|----|-----|----|----|----|----|------|------|------|------|------|------|------|-----|------------|
| | | | | | | | | | | | | | | | | | 1 to 5 |
| SLHH-6/LOK | M6x35 | 26 | 39 | 6,5 | - | - | 28 | 39 | 17,5 | 12,4 | 24,6 | 53,4 | 53,4 | 25,5 | - | 5,5 | 72,60 € |
| SLHH-8/LOK | M8x45 | 26 | 44 | 9 | - | - | 31 | 45 | 21 | 15,7 | 26,1 | 51,1 | 51,1 | 32,2 | - | 6,2 | 73,90 € |
| SLHH-10/LOK | M10x55 | 41,5 | 59 | 9 | - | - | 43 | 59 | 26 | 18,7 | 39 | 56,5 | 56,5 | 40 | - | 8,8 | 99,13 € |
| SLHH-12/LOK | M12x70 | 44 | 65 | 10 | 40 | 1 | 42 | 67 | 28 | 20,9 | 40 | 56,5 | 56,5 | 52,3 | 13,5 | 8,5 | 103,39 € |

Dimensions in mm

Horizontal toggle clamp

With locking mechanism

SLHV_{LOK}

High quality swivel bush with horizontal foot and adjustable spindle

Constant level of force during both opening and closing


Increased stability thanks to U-shaped clamping arm
Fitted with automatic locking mechanism

-Material :



Nitro carburised steel with blackened finish

Polyamide handle

Locking mechanism TPE

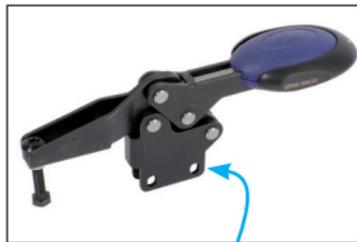

Vertical base

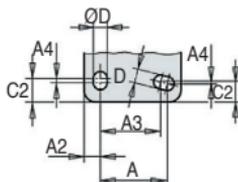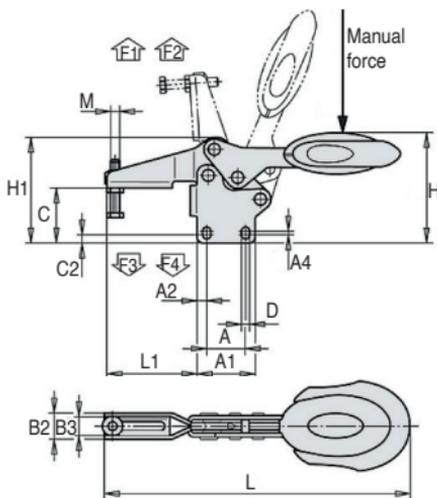

Hole positions

DISCOUNTS

| Qty | 1+ | 6+ | 15+ | 20+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | Opening angle | | Manual force N | Holding force | | Clamping force | | H | H1 | L | L1 |
|-------------|---------------|--------|-------------------|---------------|-----------|----------------|-----------|-------|-------|-------|-------|
| | Holding arm | Handle | | F1 (N) | F2 (N) | F3 (N) | F4 (N) | | | | |
| SLHV-6/LOK | 87° | 68° | 160 | 1350 | 1900 | 720 | 1200 | 74,3 | 71 | 193,7 | 60,5 |
| SLHV-8/LOK | 86° | 66° | 200 | 2000 | 2800 | 830 | 1400 | 88,3 | 84,4 | 230,3 | 74,9 |
| SLHV-10/LOK | 90° | 71° | 250 | 2200 | 4500 | 1200 | 2800 | 114,4 | 107,5 | 286,4 | 103,9 |
| SLHV-12/LOK | 88° | 68° | 280 | 2400 | 5500 | 1000 | 2800 | 128,5 | 125,2 | 321,3 | 122 |

| Part number | M | A | A1 | A2 | A3 | A4 | B | B1 | B2 | B3 | B6 | C | C2 | ØD | Price each |
|-------------|--------|------|----|-----|----|-----|------|-----|------|------|------|------|------|-----|------------|
| | | | | | | | | | | | | | | | 1 to 5 |
| SLHV-6/LOK | M6x35 | 26 | 39 | 6,5 | - | 2,5 | 14,1 | 9,1 | 17,5 | 12,4 | 53,4 | 37 | 5,5 | 5,5 | 72,60 € |
| SLHV-8/LOK | M8x45 | 26 | 44 | 9 | - | 3,5 | 14,1 | 9,1 | 21 | 15,7 | 51,1 | 46,5 | 7 | 6,2 | 73,90 € |
| SLHV-10/LOK | M10x55 | 41,5 | 59 | 9 | - | 2 | 16,2 | 9,2 | 26 | 18,7 | 56,5 | 59,6 | 8 | 8,8 | 99,13 € |
| SLHV-12/LOK | M12x70 | 44 | 65 | 10 | 40 | 1 | 16,2 | 9,2 | 28 | 20,9 | 56,5 | 75,9 | 13,5 | 8,5 | 103,39 € |

Dimensions in mm

Vertical toggle clamp

SLVH_{LOK}

With locking mechanism

High quality swivel bush with vertical foot and adjustable spindle

Constant level of force during both opening and closing


Increased stability thanks to U-shaped clamping arm
Fitted with automatic locking mechanism

- Material :

Nitro carburised steel with blackened finish

Polyamide handle

Locking mechanism TPE

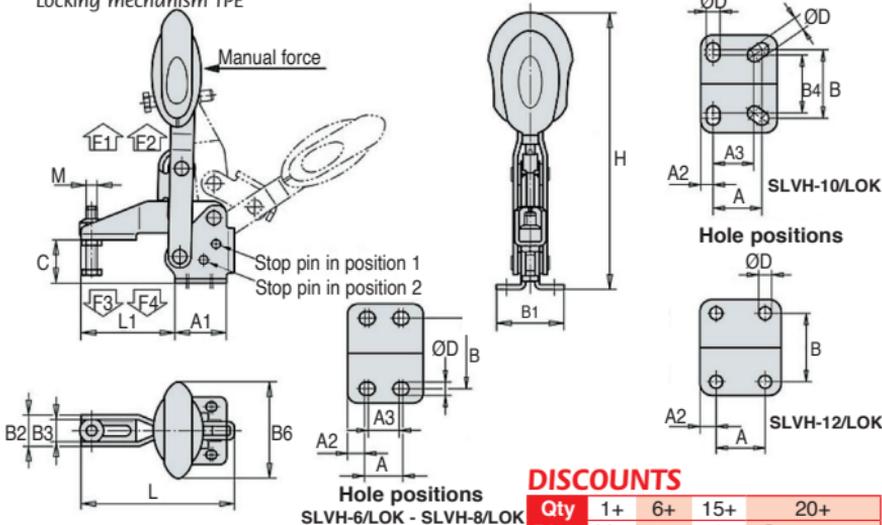

DISCOUNTS

| Qty | 1+ | 6+ | 15+ | 20+ |
|------------|-----|------|------------|-----|
| Disc. List | -5% | -10% | On request | |

| Part number | Opening angle (holding arm) | | | Opening angle (Handle) | | | Manual force (N) | Holding force | | Clamping force | |
|-------------|-----------------------------|--------|------------------|------------------------|--------|------------------|------------------|---------------|--------|----------------|--------|
| | Pos. 1 | Pos. 2 | Stop pin removed | Pos. 1 | Pos. 2 | Stop pin removed | | F1 (H) | F2 (H) | F3 (H) | F4 (H) |
| SLVH-6/LOK | 56° | 83° | 156° | 46° | 56° | 84° | 160 | 1350 | 1650 | 920 | 1050 |
| SLVH-8/LOK | 13° | 93° | 157° | 26° | 61° | 86° | 190 | 2000 | 2800 | 940 | 1350 |
| SLVH-10/LOK | 6° | 97° | 175° | 19° | 59° | 91° | 250 | 2500 | 4500 | 1500 | 2800 |
| SLVH-12/LOK | 11° | 88° | 163° | 24° | 60° | 91° | 280 | 3000 | 5500 | 1400 | 2800 |

| Part number | M | A | A1 | A2 | A3 | B | B1 | B2 | B3 | B4 | B6 | C | ØD | H | L | L1 | Price each 1 to 5 |
|-------------|--------|----|----|------|----|----|----|------|------|----|------|------|-----|-------|-------|-------|-------------------|
| SLVH-6/LOK | M6x35 | 14 | 29 | 7 | 12 | 27 | 38 | 17,5 | 12,4 | - | 53,4 | 24,7 | 5,5 | 162,9 | 86,5 | 53 | 70,38 € |
| SLVH-8/LOK | M8x45 | 21 | 39 | 9 | 19 | 32 | 45 | 20,6 | 15,5 | - | 51,1 | 32,7 | 6,8 | 191,4 | 107 | 62 | 73,44 € |
| SLVH-10/LOK | M10x55 | 32 | 50 | 8 | 27 | 45 | 64 | 25,5 | 18,4 | 38 | 56,5 | 38,7 | 9 | 230,5 | 153 | 95 | 100,63 € |
| SLVH-12/LOK | M12x70 | 32 | 53 | 10,5 | - | 45 | 63 | 28 | 20,9 | - | 56,5 | 46,7 | 8,8 | 249,1 | 173,5 | 113,5 | 104,03 € |

Dimensions in mm

Vertical toggle clamp

With locking mechanism SLVV_{LOK}

High quality swivel bush with vertical foot and adjustable spindle



Constant level of force during both opening and closing
Increased stability thanks to U-shaped clamping arm
Fitted with automatic locking mechanism

- Material :

Nitro carburised steel with blackened finish

Polyamide handle

Locking mechanism TPE

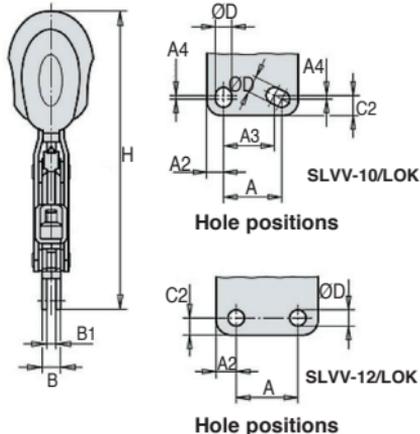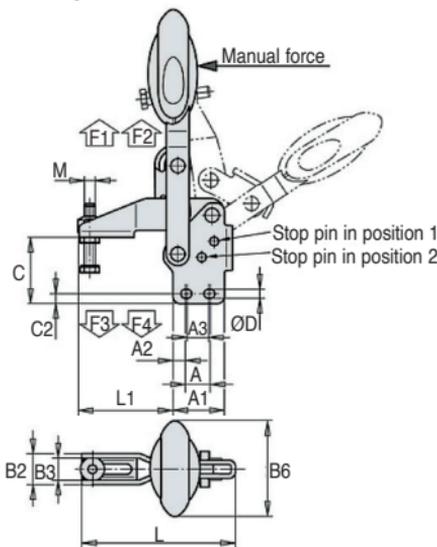

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 15+ | 20+ |
| Disc. | List | -5% | -10% | On request |

| Part number | Opening angle (Holding arm) | | | Opening angle (Handle) | | | Manual force (N) | Holding force | | Clamping force | |
|-------------|-----------------------------|--------|------------------|------------------------|--------|--------|------------------|---------------|--------|----------------|--|
| | Pos. 1 | Pos. 2 | Stop pin removed | Pos. 1 | Pos. 2 | F1 (N) | | F2 (N) | F3 (N) | F4 (N) | |
| SLVV-6/LOK | 56° | 83° | 156° | 46° | 56° | 160 | 1350 | 1650 | 920 | 1050 | |
| SLVV-8/LOK | 13° | 93° | 157° | 26° | 61° | 190 | 2000 | 2800 | 940 | 1350 | |
| SLVV-10/LOK | 6° | 97° | 175° | 19° | 59° | 250 | 2500 | 4500 | 1500 | 2800 | |
| SLVV-12/LOK | 11° | 88° | 163° | 24° | 60° | 280 | 3000 | 5500 | 1400 | 2800 | |

| Part number | M | A | A1 | A2 | A3 | A4 | B | B1 | B2 | B3 | B6 | C | C2 | ØD | H | L | L1 | Price each 1 to 5 |
|-------------|--------|----|----|------|----|-----|------|-----|------|------|------|------|-----|-----|-------|-------|-------|-------------------|
| SLVV-6/LOK | M6x35 | 14 | 29 | 7 | 12 | - | 10,2 | 5,2 | 17,5 | 12,4 | 53,4 | 37,6 | 5,5 | 5,5 | 175,7 | 86,5 | 53 | 70,38 € |
| SLVV-8/LOK | M8x45 | 21 | 39 | 9 | 19 | - | 10,2 | 5,2 | 20,6 | 15,5 | 51,1 | 49 | 6,5 | 6,8 | 207,6 | 107 | 62 | 73,44 € |
| SLVV-10/LOK | M10x55 | 32 | 50 | 8 | 27 | 3,5 | 14,1 | 7,1 | 25,5 | 18,4 | 56,5 | 62,3 | 13 | 9 | 254 | 153 | 95 | 100,63 € |
| SLVV-12/LOK | M12x70 | 32 | 53 | 10,5 | - | - | 14,1 | 7,1 | 28 | 20,9 | 56,5 | 69,8 | 9 | 8,8 | 271,9 | 173,5 | 113,5 | 104,03 € |

Dimensions in mm

Nut for toggle clamps

SLH-M

Round ended nut



- Nut for toggle clamps

- Material : steel

- Finish : oxidised

Advantage

- Nut can be welded

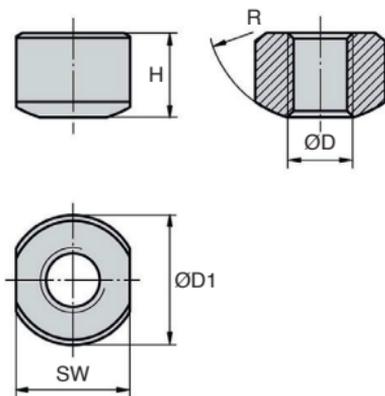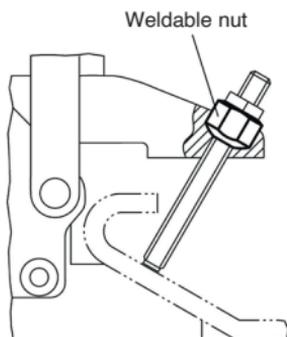

DISCOUNTS

| Qty | 1+ | 6+ | 15+ | 20+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | ØD | H | ØD1 | SW | R | Price each |
|-------------|-----|------|------|------|----|------------|
| | | | | | | 1 to 5 |
| SLH-M4 | M4 | 5,2 | 8 | 7 | 7 | 3,36 € |
| SLH-M5 | M5 | 6,7 | 10 | 9 | 9 | 3,55 € |
| SLH-M6 | M6 | 9,5 | 13,5 | 12,2 | 10 | 3,89 € |
| SLH-M8 | M8 | 12,8 | 18 | 15,3 | 12 | 4,44 € |
| SLH-M10 | M10 | 12,1 | 20 | 18,2 | 14 | 4,74 € |
| SLH-M12 | M12 | 14,8 | 23 | 20 | 16 | 5,14 € |

Dimensions in mm

Locking toggle clamps

Quick clamping - solid mounting

Durable and reliable: More reliable, more user-friendly and safer. These clamps are quick to use, reliable and accurate. The use of high quality materials ensures a long working life.


Advantages

- **Extremely tough** : All models will withstand 300,000 clamping cycles without problems
- **Durable**: high quality scratch resistant hinge pin
- **Extremely robust** : tCorrosion-resistant NITROX coating
- **Easy to use**: The fixed headed nut facilitates spindle adjustment
- **Reliable**: Constant level of force during both opening and closing
- **Ideal where space is restricted**: The slim design allows sufficient space for safe operation
- **Robust by design**: Thanks to use of U-shaped conical clamping arm
- **Safe to use**: No sharp edges prevent risk of anything getting trapped
- **Quick to put into operation**: Can be easily modified thanks to a wide range of accessories
- **Ergonomic design**: Easy to operate whilst wearing work gloves
- **Reflection free finish**: Suitable for use around lasers
- **Risk free use**: With increased space between clamping arm and handle avoids risks of squashing
- **Extremely adaptable**: Rectangular mounting holes allows installation on existing fixing points
- **Efficient clamping and locking**: The integrated design avoids any risks of squashing. Easy to use even whilst wearing gloves.

Locking mechanism - Principal of operation:



1. Locked in closed position. Redesigned handle ensures safe operation as the smooth contours avoid any risk of anything being trapped.

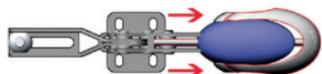

2. Inner locking mechanism with automatic safety catch. The lock is released by pulling the handle.



3. Locked in open position. Releasing the handle engages the locking mechanism.

