

- 2 materials to choose from

- Materials:

SEH body: zinc plated steel

SEH/SS body: stainless steel 18.9 (303)

Handle: Oil-resistant plastic


- Supplied with anchoring base

Advantages

- Distance of hook from toggle clamp easily adjustable

Uses

- Designed to secure covers and shutters

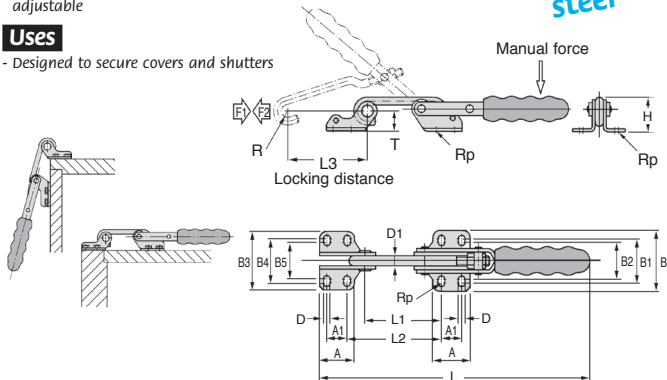

DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Size	Traction force F1 (N)	Pressure F2 (N)	Manual force (N)	Handle opening angle	L	L1	L2	Locking distance L3	A	A1
SCH-01	1500	2000	100	155°	161	45	58	70	26	13
SCH-02	3000	4000	160	155°	248	68	84	90	35	19
SCH-04	4000	7000	200	155°	310	84	104	115	51	32

Part number	Material		Dimensions (mm)								Stock*		Price each 1 to 5				
	Steel	Stainless steel	B	B1	B2	B3	B4	B5	D	D1	H	R	T	Steel	StS	Steel	StS
SCH-0130	SCH-0130SS		39	27,0	22,2	43	31	26	5,2	6	26	6	13,5	✓	✓	49,79 €	58,05 €
SCH-0270	SCH-0270SS		52	36,0	29,0	57	41	34	6,5	8	35	7	20,0	✓	✓	73,57 €	87,73 €
SCH-0430	SCH-0430SS		72	52,5	43,5	78	59	50	8,5	12	49	10	27,0	-	-	93,21 €	183,19 €

*Subject to availability - Dimensions in mm

Our other products



SLB
Indexing plunger,
steel class 5.8



NT62
Spur gear coaxial
gearbox, from 6 to 18
Nm - In-line



PTA80
Articulated levelling
foot, pressed base
Ø80, Ø 80



WINGbrEcrou
Manually tightened
wing nut DIN315,
Brass DIN 315



NKXR
Combined bearing
without inner ring,
Needle and cylindrical
rollers



RESC
Retractable castor for
aluminium profile,
Retractable castor



ZBconique
Machined plastic
bevel gear, 1:1



 
UCF_PBT
Stainless
steel/Polymer flanged
bearing, Polymer and
stainless steel



APB_F
Adjusting rod for
clamp - Male,
Threaded



Q1
Self-aligning radial
ball bearing, Steel



GPLac
Brush, steel



ERF
Quick fitting threaded
cable terminal, Cable
terminal with
threaded ...

Complementary products



SCH
Horizontal hook
toggle clamp,
Horizontal Hook
clamp - steel