

### - 2 materials to choose from

- Materials:

**SEH** body: zinc plated steel

**SEH/SS** body: stainless steel 18.9 (303)

Handle: Oil-resistant plastic


- Supplied with anchoring base

### Advantages

- Distance of hook from toggle clamp easily adjustable

### Uses

- Designed to secure covers and shutters

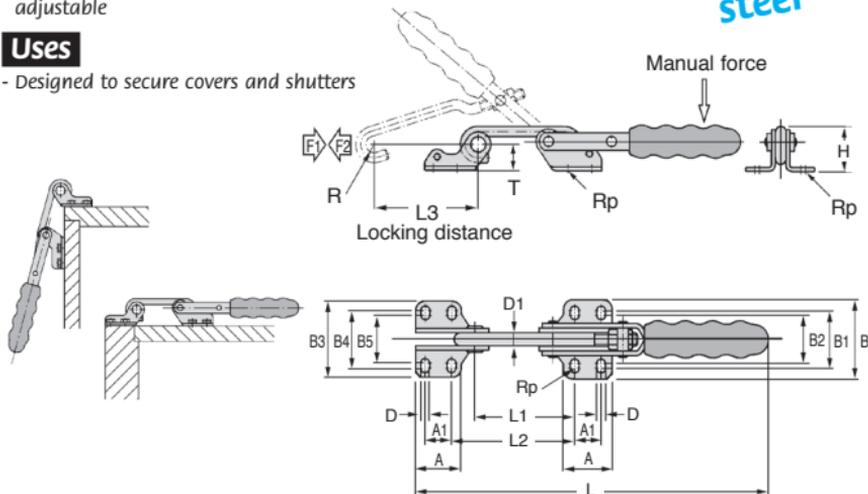

### DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Size	Traction force F1 (N)	Pressure F2 (N)	Manual force (N)	Handle opening angle	L	L1	L2	Locking distance L3	A	A1
SCH-01	1500	2000	100	155°	161	45	58	70	26	13
SCH-02	3000	4000	160	155°	248	68	84	90	35	19
SCH-04	4000	7000	200	155°	310	84	104	115	51	32

Part number												Stock*		Price each 1 to 5		
Steel	Stainless steel	B	B1	B2	B3	B4	B5	D	D1	H	R	T	Steel	StS	Steel	StS
SCH-0130	SCH-0130SS	39	27,0	22,2	43	31	26	5,2	6	26	6	13,5	✓	✓	49,79 €	58,05 €
SCH-0270	SCH-0270SS	52	36,0	29,0	57	41	34	6,5	8	35	7	20,0	✓	✓	73,57 €	87,73 €
SCH-0430	SCH-0430SS	72	52,5	43,5	78	59	50	8,5	12	49	10	27,0	-	-	93,21 €	183,19 €

\*Subject to availability - Dimensions in mm

## Our other products



CHM50

Worm and wheel gear reducer, up to 107 Nm



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze



SHS

Shoulder screw stainless steel 303, Stainless steel 303




UCFL PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



SLB

Indexing plunger, steel class 5.8

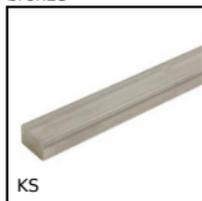

KS

Keysteel, Stainless steel - Keystock



BABFCFO

Ball pin socket, Mounting collar with a oval flange



CHTRP

Single and dual output gearboxes, Up to 28,8 Nm



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



PRF-SMA

Closing system for aluminium profile, Easily adjustable lock



LRR

Spring loaded latch, Spring loaded latch



TPR

High helix leadscrew, Leadscrew only - up to 40mm per rotation

## Complementary products



SCH

Horizontal hook toggle clamp, Horizontal Hook clamp - steel