


Suction cup threaded insert


Socket screw

SCR
ADAG

- Material: nickel brass

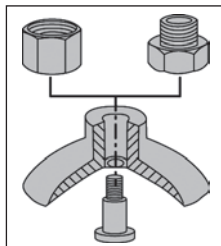


Assembly diagram

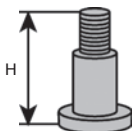


Socket screw insert



Adaptor

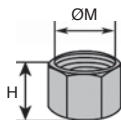

female

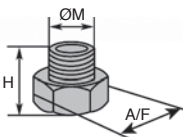

male

DISCOUNTS

Qty	1+	50+	100+	150+	200+
Disc. List	-5%	-10%	-15%	On request	

Insert socket head

Part number	Ø	H	For suction cup	For adaptor	Stock*	Price each 1 to 49
SCR15M5	M5	9	DFG15	ADAG18M5F	✓	2,21 €
SCR20M5	M5	11	DFG20	ADAG18F5F	✓	3,28 €
SCR30M6	M6	19	DCA33, DCA43, DCG30, DCG40, DCG60	ADAG18F6F, ADAG18M6F	✓	1,85 €
SCR20BM6	M6	14	DFG25, DFG30, DFG40	ADAG14F6F	✓	3,28 €
SCR50M6	M6	17	DFG50	ADAG14M6F	✓	4,59 €

DISCOUNTS


Qty	1+	50+	100+	150+	200+
Disc. List	-5%	-10%	-15%	On request	

Adaptor

Part number	ØM	H	A/F	For socket screw insert	Stock*	Price each 1 to 49
ADAG18F6F	1/8»	14,0	13	female	-	2,21 €
ADAG14F6F	1/4»	17,5	17	female	-	2,89 €
ADAG18M6F	1/8»	13,0	13	male	✓	2,21 €
ADAG14M6F	1/4»	15,0	17	male	✓	2,21 €
ADAG18M5F	1/8»	13,0	13	male	✓	2,89 €
ADAG18F5F	1/8»	14,0	13	female	-	3,13 €

*Depending on availability - Dimensions in mm

 Our other products



NANO

Speed controller 3A, 3 A



PRF JL2

Lip seal for panel,
Door seal - Ø 2mm



RFV40

Stainless steel worm
and wheel gearbox,
up to 47 Nm



NSB

Standard linear
bearing housing,
Closed - Long



PRS80

Stainless steel
articulated foot Ø80,
Ø 80



SH0

Parallel axis helical
gear, Machined plastic
(delrin)



EF5M

Igubal® flange
bearing, Polymer



T5M T10M

T type timing belt per
metre, T5 Steel cored
polyurethane



BPP

Pressed steel flanged
bearing for light




GAL21

Conveyor wheel,
Plastic



H1

 Crossed helical gear
crossed axis at 90°,



PRF CHA D

Hinge and joint, Lift-
off hinge

Complementary products



SCR

Suction cup threaded
insert, Adaptor for
insert



DCG

Suction cup, 2.5
bellows, nitrile