


Suction cup threaded insert


Socket screw

SCR
ADAG

- Material: nickel brass

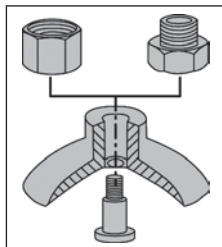


Assembly diagram

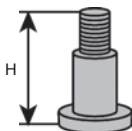


Socket screw insert



Adaptor

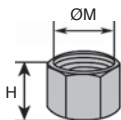

female

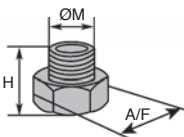

male

DISCOUNTS

Qty	1+	50+	100+	150+	200+
Disc. List	-5%	-10%	-15%	On request	

Insert socket head

Part number	Ø	H	For suction cup	For adaptor	Stock*	Price each 1 to 49
SCR15M5	M5	9	DFG15	ADAG18M5F	✓	2,21 €
SCR20M5	M5	11	DFG20	ADAG18F5F	✓	3,28 €
SCR30M6	M6	19	DCA33, DCA43, DCG30, DCG40, DCG60	ADAG18F6F, ADAG18M6F	✓	1,85 €
SCR20BM6	M6	14	DFG25, DFG30, DFG40	ADAG14F6F	✓	3,28 €
SCR50M6	M6	17	DFG50	ADAG14M6F	✓	4,59 €

DISCOUNTS

Qty	1+	50+	100+	150+	200+
Disc. List	-5%	-10%	-15%	On request	

Adaptor

Part number	ØM	H	A/F	For socket screw insert	Stock*	Price each 1 to 49
ADAG18F6F	1/8»	14,0	13	female	-	2,21 €
ADAG14F6F	1/4»	17,5	17	female	-	2,89 €
ADAG18M6F	1/8»	13,0	13	male	✓	2,21 €
ADAG14M6F	1/4»	15,0	17	male	✓	2,21 €
ADAG18M5F	1/8»	13,0	13	male	✓	2,89 €
ADAG18F5F	1/8»	14,0	13	female	-	3,13 €

*Depending on availability - Dimensions in mm

Our other products



SHA_PTR
Handwheel with
folding handle,
Polyamide



CDPC
Flanged drill bushing,
Steel



BPPL
Mini plain bearing ball
transfer unit, For
countersinking




CLG1
Moulded plastic spur
gear, Moulded plastic
(nylon)



FF20
Offset spur gear
reducer, from 5.80 to
23 Nm



SRP
Slotted spring pin
ISO8752, Split ISO
8752

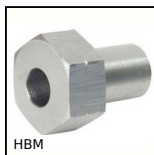


HBM
Adjustment bushing
for half-rail guide,
Adjustment bushing



SCE
U-shaped cable
clamp, Steel



 CHTRP
Single and dual
output gearboxes, Up



TPR
High helix leadscrew,
Leadscrew only - up



BOX-TOR-ORFS
Box set of Nitrile O-
rings NBR90Sh A, 7.65



GB-RA
Brass spur gear, Brass
CuZn39Pb3

Complementary products



SCR
Suction cup threaded
insert, Insert for
suction cup - Socket
screw