



# Locating bolt support bracket

Stock

**SDA** Mounting holes parallel to locating bolt

- Use of a support bracket allows locating bolts to be positioned quickly
- Compatible with all types of locating bolts
- Material: blackened steel

Positioned quickly

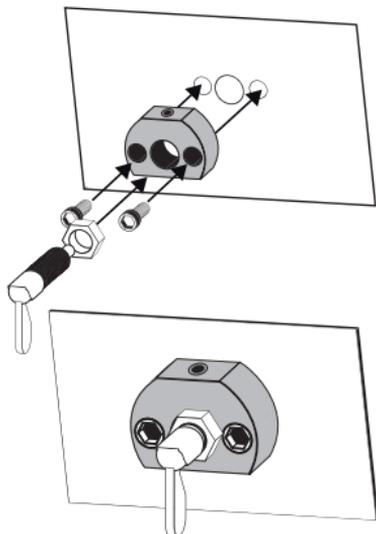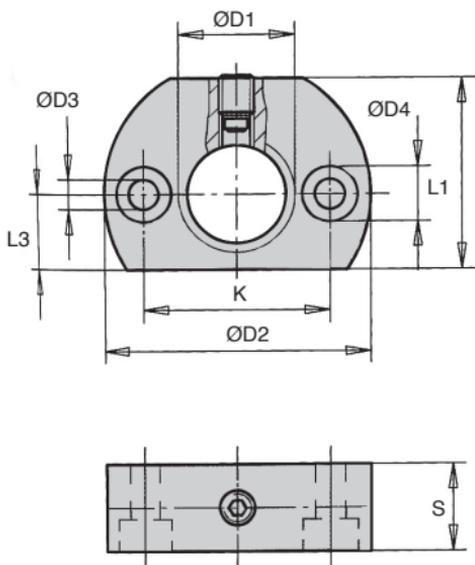

## DISCOUNTS



Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	ØD1	ØD2	ØD3	ØD4	K	L1	L3	S	Stock*	Price each 1 to 5
SDA12	M12	36	5,5	10	24	25	10	12	✓	14,00 €
SDA12-F	M12 x 1,5	36	5,5	10	24	25	10	12	-	14,00 €
SDA16	M16	46	5,5	10	32	33	13	15	✓	15,19 €
SDA16-F	M16 x 1,5	46	5,5	10	32	33	13	15	✓	15,19 €
SDA20	M20	46	5,5	10	32	33	13	15	✓	19,09 €
SDA20-F	M20 x 1,5	46	5,5	10	32	33	13	15	✓	15,19 €

\*Depending on availability - Dimensions in mm

- Use of a support bracket allows locating bolts to be mounted quickly
- Compatible with all types of locating bolts
- Material:  
Body: blackened steel

Positioned quickly

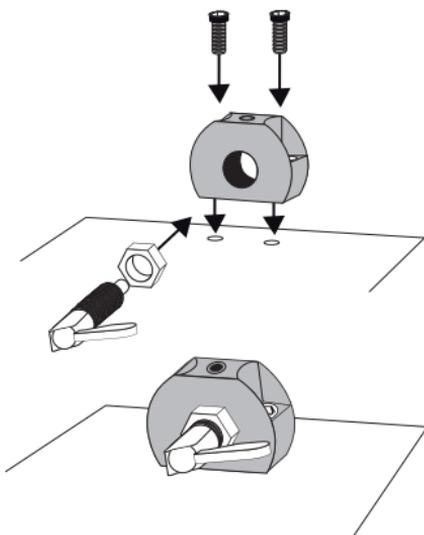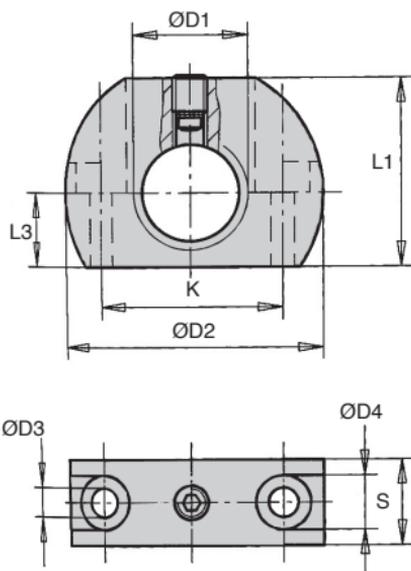

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	ØD1	ØD2	ØD3	ØD4	K	L1	L3	S	Stock*	Price each 1 to 5
SDB12	M12	36	5,5	10	24	25	10	12	✓	18,45 €
SDB12-F	M12 x 1,5	36	5,5	10	24	25	10	12	✓	18,45 €
SDB16	M16	46	5,5	10	32	33	13	15	✓	18,29 €
SDB16-F	M16 x 1,5	46	5,5	10	32	33	13	15	✓	18,29 €
SDB20	M20	46	5,5	10	32	33	13	15	✓	21,47 €
SDB20-F	M20 x 1,5	46	5,5	10	32	33	13	15	✓	17,82 €

\*Depending on availability - Dimensions in mm

# Positioning sleeve for indexing pin New


## SDC

## For pin Ø4 to Ø12


- Suitable for indexing pins and indexing locks
- Low wear due to hardened cone
- Materials:
  - Hardened and burnished steel
  - Hardened stainless steel

### Accessories

- Compatible with the SDA and SDB locating bolt support bracket (tome 1 p.76-77)
- Compatible with the HPC range of indexing pins.

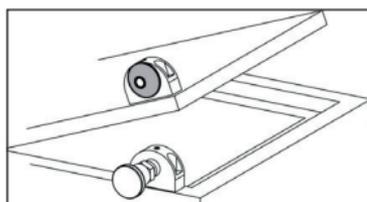

Application example

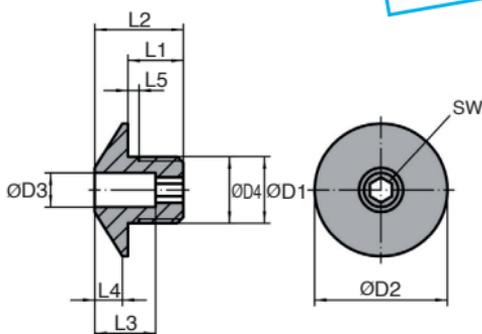

### DISCOUNTS

Qty	1+	6+	20+
Disc.	Price -10%	On request	On request

Part number	ØD	ØD3	ØD4	L				L5	For	Weight	Price each		
		(+0,1)	ØD2 (-0,05)	L1	L2	L3	L4	(+0,5)				pin diam	SW
<b>Steel</b>													
SDC12F-4	M12X1,5	4,2	24	12	10	16	11	5	1,5	4	4	17	11,88 €
SDC12F-5	M12X1,5	5,2	24	12	10	16	11	5	1,5	5	4	16	11,95 €
SDC12F-6	M12X1,5	6,2	24	12	10	16	11	5	1,5	6	4	16	11,95 €
SDC16F-8	M16X1,5	8,2	32	16	12	20	13	7	1,5	8	6	32	14,34 €
SDC16F-10	M16X1,5	10,2	32	16	12	20	13	7	1,5	10	6	33	14,24 €
SDC16F-12	M16X1,5	12,2	32	16	12	20	13	7	1,5	12	6	33	14,34 €
<b>Stainless steel</b>													
SDC12F-4/SS	M12X1,5	4,2	24	12	10	16	11	5	1,5	4	4	17	15,95 €
SDC12F-5/SS	M12X1,5	5,2	24	12	10	16	11	5	1,5	5	4	16	15,95 €
SDC12F-6/SS	M12X1,5	6,2	24	12	10	16	11	5	1,5	6	4	16	15,95 €
SDC16F-8/SS	M16X1,5	8,2	32	16	12	20	13	7	1,5	8	6	32	23,19 €
SDC16F-10/SS	M16X1,5	10,2	32	16	12	20	13	7	1,5	10	6	33	23,19 €
SDC16F-12/SS	M16X1,5	12,2	32	16	12	20	13	7	1,5	12	6	33	23,19 €

Dimensions in mm