

# Positioning sleeve for indexing pin New


## SDC

## For pin Ø4 to Ø12


- Suitable for indexing pins and indexing locks
- Low wear due to hardened cone
- Materials:
  - Hardened and burnished steel
  - Hardened stainless steel

### Accessories

- Compatible with the SDA and SDB locating bolt support bracket (tome 1 p.68-69)
- Compatible with the HPC range of indexing pins.

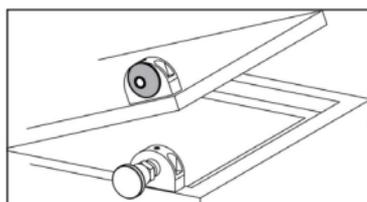

Application example

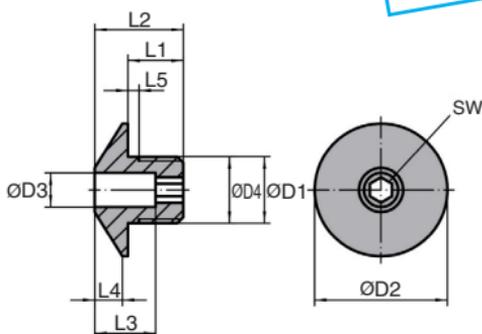

### DISCOUNTS

Qty	1+	6+	20+
Disc.	Price -10%	On request	On request

Part number	ØD	ØD3		ØD4		L5			For pin diam	Weight (g)	Price each 1 to 5		
		(+0,1)	ØD2	(-0,05)	L1	L2	L3	L4				(+0,5)	
<b>Steel</b>													
SDC12F-4	M12X1,5	4,2	24	12	10	16	11	5	1,5	4	4	17	9,49 €
SDC12F-5	M12X1,5	5,2	24	12	10	16	11	5	1,5	5	4	16	9,55 €
SDC12F-6	M12X1,5	6,2	24	12	10	16	11	5	1,5	6	4	16	9,55 €
SDC16F-8	M16X1,5	8,2	32	16	12	20	13	7	1,5	8	6	32	11,46 €
SDC16F-10	M16X1,5	10,2	32	16	12	20	13	7	1,5	10	6	33	11,38 €
SDC16F-12	M16X1,5	12,2	32	16	12	20	13	7	1,5	12	6	33	11,46 €
<b>Stainless steel</b>													
SDC12F-4/SS	M12X1,5	4,2	24	12	10	16	11	5	1,5	4	4	17	12,75 €
SDC12F-5/SS	M12X1,5	5,2	24	12	10	16	11	5	1,5	5	4	16	12,75 €
SDC12F-6/SS	M12X1,5	6,2	24	12	10	16	11	5	1,5	6	4	16	12,75 €
SDC16F-8/SS	M16X1,5	8,2	32	16	12	20	13	7	1,5	8	6	32	18,53 €
SDC16F-10/SS	M16X1,5	10,2	32	16	12	20	13	7	1,5	10	6	33	18,53 €
SDC16F-12/SS	M16X1,5	12,2	32	16	12	20	13	7	1,5	12	6	33	18,53 €

Dimensions in mm

## Our other products



RBN  
Wheel, Rubber tyre -  
Polypropylene rim



DOMI80  
Connecting kits, XZ  
linking kit



HW\_HT  
Half-rail guide, Wheel



ZDB  
Machined plastic  
bevel gear , 2:1



CHB  
Single output shaft,  
For CHB gearbox



ZBconique  
Machined plastic  
bevel gear, 1:1



CHMR90  
Worm and wheel gear  
reducer, up to 540  
Nm



PRF1932  
Standard aluminium  
profile, 19 x 32 mm



CHV  
Mechanical speed  
variator, from 0,18 to  
1,5kW



CAP880  
Side flexing slim slat  
top chain acetal,  
Narrow range 880



CHAGC-AL  
Screw-in garnet  
hinge, Screw-on



RFK28C  
Hypoid gearbox -  
Stainless steel, up to  
130 Nm

## Complementary products



SDC  
Positioning sleeve for  
indexing pin, For pin  
Ø4 to Ø12



SDA  
Locking bolt support  
bracket, Mounting  
holes parallel to  
locating bolt



SDB  
Locking bolt support  
bracket, Mounting  
holes at 90° to  
locating bolt



SLB  
Indexing plunger,  
steel class 5.8