

# Positioning sleeve for indexing pin New


## SDC

## For pin Ø4 to Ø12


- Suitable for indexing pins and indexing locks
- Low wear due to hardened cone
- Materials:  
Hardened and burnished steel  
Hardened stainless steel

### Accessories

- Compatible with the SDA and SDB locating bolt support bracket (tome 1 p.68-69)
- Compatible with the HPC range of indexing pins.

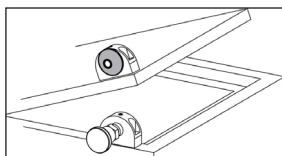

Application example

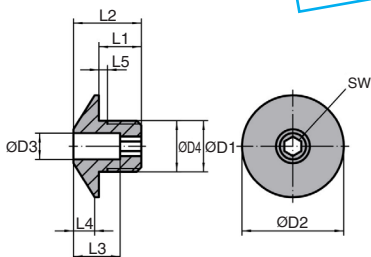

### DISCOUNTS

Qty	1+	6+	20+
Disc.	Price -10%	On request	On request

Part number	ØD	ØD3		ØD4		L5				For pin diam	Weight (g)	Price each 1 to 5	
		(+0,1)	ØD2	(-0,05)	L1	L2	L3	L4	(+0,5)				
<b>Steel</b>													
SDC12F-4	M12X1,5	4,2	24	12	10	16	11	5	1,5	4	4	17	9,49 €
SDC12F-5	M12X1,5	5,2	24	12	10	16	11	5	1,5	5	4	16	9,55 €
SDC12F-6	M12X1,5	6,2	24	12	10	16	11	5	1,5	6	4	16	9,55 €
SDC16F-8	M16X1,5	8,2	32	16	12	20	13	7	1,5	8	6	32	11,46 €
SDC16F-10	M16X1,5	10,2	32	16	12	20	13	7	1,5	10	6	33	11,38 €
SDC16F-12	M16X1,5	12,2	32	16	12	20	13	7	1,5	12	6	33	11,46 €
<b>Stainless steel</b>													
SDC12F-4/SS	M12X1,5	4,2	24	12	10	16	11	5	1,5	4	4	17	12,75 €
SDC12F-5/SS	M12X1,5	5,2	24	12	10	16	11	5	1,5	5	4	16	12,75 €
SDC12F-6/SS	M12X1,5	6,2	24	12	10	16	11	5	1,5	6	4	16	12,75 €
SDC16F-8/SS	M16X1,5	8,2	32	16	12	20	13	7	1,5	8	6	32	18,53 €
SDC16F-10/SS	M16X1,5	10,2	32	16	12	20	13	7	1,5	10	6	33	18,53 €
SDC16F-12/SS	M16X1,5	12,2	32	16	12	20	13	7	1,5	12	6	33	18,53 €

Dimensions in mm

## Our other products



RPP  
Connecting plate for  
RPP type timing belts,  
RPP8



PCS50SS  
Chain sprocket -  
Stainless steel,  
12.7mm (DIN 08B-1)



KK  
Rounded end feather key,  
Steel



GE  
Toggle latches,  
Miniature



TPEpbd  
Castor for aluminium  
profile, Swivel with  
brake



MSP19  
Masterplate®  
glueable insert Ø19,  
Cylindrical with  
tapped insert




BFM2  
Flanged bronze nut,  
Bronze - 2 threads



HG6-ECO  
Eco range Spur gear,  
Steel C45



 
PSG2S  
Spur gear - precision  
range, Stainless steel  
303



PRF-SCREEN-1  
Screen support, Basic  
support



HLC24  
Right angle spiro  
bevel gearbox, Up to  
78Nm

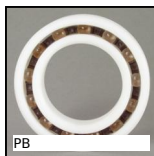

PB  
Plastic deep groove  
ball bearing, Plastic -  
glass balls material

## Complementary products



SDC  
Positioning sleeve for  
indexing pin, For pin  
Ø4 to Ø12



SDA  
Locking bolt support  
bracket, Mounting  
holes parallel to  
locating bolt



SDB  
Locking bolt support  
bracket, Mounting  
holes at 90° to  
locating bolt



SLB  
Indexing plunger,  
steel class 5.8