

Guide support bracket

Pla  Stock 

SDG

Plastic

- Guide support for bottling and packaging applications

- Materials:

Support: reinforced polyamide

Spacer: stainless steel

Threaded inserts: nickel brass

- Weight: 0.20 kg

Info.

- Not sold individually, please contact us for details

Accessories


- Guides GMC, GMK

- Clamps GMC-BR, GMK-BR



- Adjusting rod APB-T or APB-F



Quick adjustment

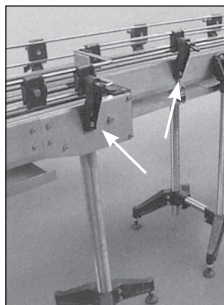

Typical application

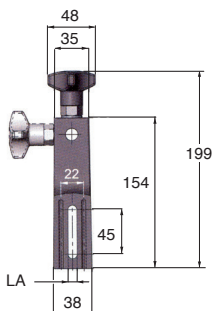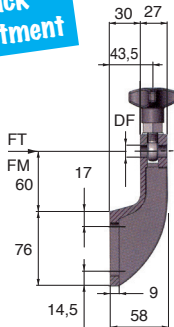

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-5%	On request

Part number	DF	LA	FT (N)	FM (N)	Stock*	Price each 1 to 19
SDG10-12	12,5	10,5	2000	4000	✓	12,36 €
SDG10-14	14,5	10,5	3000	4000	✓	12,26 €
SDG10-16	16,5	10,5	3000	4000	✓	13,87 €

*Depending on availability - Dimensions in mm

Our other products



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



 
LC

Friction clutch, 190 to 1800 Nm



RLX

Free running conveyor roller, PVC



CXS

External circlip DIN471, external DIN 471



CLQassortiment

Assorted feeler strips, Assorted feeler strips



BPM

Slotted spring plunger with ball tip, Steel



BH02

Single housed bearing assembly, Bearing secured with circlips



GGP

Male wing knob, Technopolymer with brass spindle



ADSR

Backlash free coupling Gerwah®, from 12.5 to 525Nm



LBE

Miniature closed linear bearing, Miniature



PFM


Fixed levelling foot, Flanged plate



SVR20

Screwjack with travelling nut, with moving nut

 Complementary products



GMC

Flat profile - Round guide, Flat profile - round guide



SDG_SS

Universal adjustable guide support bracket, Stainless steel



APB_F

Adjusting rod for clamp - Male, Threaded



GDR880

Straight track for slat top chain, Ranges 880 and 881