

Guide support bracket

Pla  Stock

SDG

Plastic

- Guide support for bottling and packaging applications

- Materials:

Support: reinforced polyamide

Spacer: stainless steel

Threaded inserts: nickel brass

- Weight: 0.20 kg

Info.

- Not sold individually, please contact us for details

Accessories


- Guides GMC, GMK

- Clamps GMC-BR, GMK-BR



- Adjusting rod APB-T or APB-F



Quick adjustment

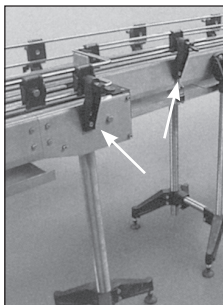

Typical application

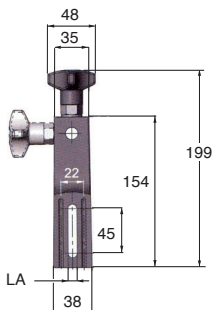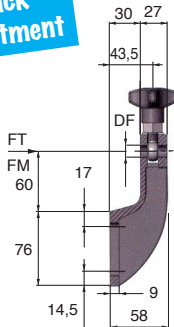

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-5%	On request

Part number	DF	LA	FT (N)	FM (N)	Stock*	Price each 1 to 19
SDG10-12	12,5	10,5	2000	4000	✓	12,36 €
SDG10-14	14,5	10,5	3000	4000	✓	12,26 €
SDG10-16	16,5	10,5	3000	4000	✓	13,87 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze



RVM14

Manual worm and wheel gearbox, Worm/wheel



PRF_ECL

Nut for aluminium profile, Stainless steel square nut with tab



WJUM20

Drylin® W bearing block, Slide



GP

Spring loaded toggle latch, With padlock-holder



BWU

Compact precision slide, from 1510 N to 10500 N



BAC110

Swivel storage bin, Adjustable support



J51

Spur gear coaxial gearbox, from 0.13 to 0.49 Nm - In-line



PM4

Worm and wheel set, Non hardened steel



BAG0

Locking rings in stainless steel, Stainless steel



PSG25

 
Spur gear - precision range, Stainless steel 316



PGNT

Thermoplastic T handle, With threaded insert

Complementary products



GMC

Flat profile - Round guide, Flat profile - round guide



SDG_SS

Universal adjustable guide support bracket, Stainless steel



APB_F

Adjusting rod for clamp - Male, Threaded



GDR880

Straight track for slat top chain, Ranges 880 and 881