



- Guide support for bottling and packaging applications
- Materials:
 - reinforced polyamide
 - stainless steel
 - nickel brass (threaded inserts)
- Not sold individually, please contact us for details

Accessories

- Guide GMC
- Clamps GMC-BR
- Adjusting rod Ø12, Ø14 and Ø16 APB-F

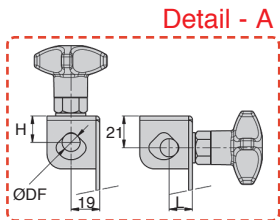

For hostile environments

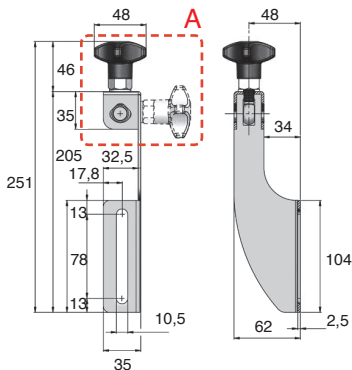

DISCOUNTS

Qty	1+	20+	50+
Disc. List		-5%	On request

Part number	ØDF	H	L	Weight (kg)	Stock*	Price each 1 to 19
SDG10-UNI/SS	12	18	16	0,33	✓	23,43 €
	14	19	17			
	16	20	19			

*Depending on availability - Dimensions in mm

Our other products



CLQassortment

Assorted feeler strips,
Assorted feeler strips



PCP

Cell carrier assembly,
Ready assembled



ZBconique

Machined plastic
bevel gear, 1:1



RFK58B

Hypoid gearbox -
Stainless steel, up to
500 Nm



CHAR7530

Spring hinge, welded



PW_PWG15

Wheel - precision
range, Bronze



BEAS

Star shaped anti-
static handle, Star,
anti-static



FF50

Offset spur gear
reducer, from 111 to
425 Nm



EMAS

Antistatic knurled nut,
Antistatic



KSM

Cylindrical steel nut,
Steel - 1 thread



HW_HT

 
Half-rail guide, Rail



NSKB

Drylin® Rail end cap,
Rail end cap

Complementary products



GMC

Flat profile - Round
guide, Flat profile -
round guide



SDG

Adjustable guide
support bracket,
Plastic



APB_F

Adjusting rod for
clamp - Male,
Threaded



APB_T

Adjusting rod for
clamp - Female, Bored