

Guide support bracket



SDG

Plastic

- Guide support for bottling and packaging applications

- Materials:

Support: reinforced polyamide

Spacer: stainless steel

Threaded inserts: nickel brass

- Weight: 0.20 kg

Info.

- Not sold individually, please contact us for details

Accessories


- Guides GMC, GMK

- Clamps GMC-BR, GMK-BR



- Adjusting rod APB-T or APB-F



Quick adjustment

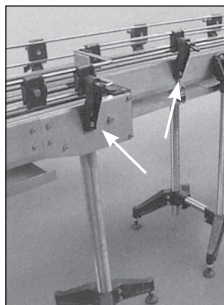

Typical application

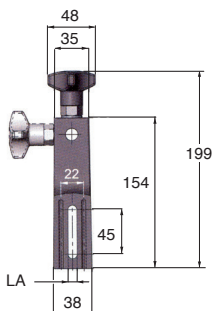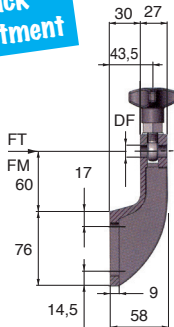

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-5%	On request

Part number	DF	LA	FT (N)	FM (N)	Stock*	Price each 1 to 19
SDG10-12	12,5	10,5	2000	4000	✓	12,36 €
SDG10-14	14,5	10,5	3000	4000	✓	12,26 €
SDG10-16	16,5	10,5	3000	4000	✓	13,87 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020


www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products




EIM
Stainless steel U bolt,
Stainless steel

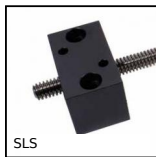

SLS
Bearing block for
leadscrew, Fixed
Drylin® bearing block



VCMB
Dual-thread screw
wood/metal, Stainless
steel

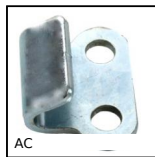

AC
Strike for toggle latch,
18mm



AKN
Bellows coupling
Gerwah®, from 22 to
180Nm



 
BPP
Pressed steel flanged
bearing for light
loads, Sheet steel



MDB_MTB
Moulded plastic bevel
gear (nylon), 2:1



BSM_LOK
Long-Lok spring
plunger with internal
hexagonal socket,
LONG-LOK - s...



POA
Magnetic workshop
tool support, Magnetic



PRS100
Stainless steel
articulated foot Ø100,




BLHB60
Right angled gearbox,
bored shafts, up to 70



PM4
Worm and wheel set,
Hardened steel

 Complementary products



GMC
Flat profile - Round
guide, Flat profile -
round guide



SDG_SS
Universal adjustable
guide support
bracket, Stainless
steel



APB_F
Adjusting rod for
clamp - Male,
Threaded



GDR880
Straight track for slat
top chain, Ranges 880
and 881