



- Guide support for bottling and packaging applications
- Materials:
 - reinforced polyamide
 - stainless steel
 - nickel brass (threaded inserts)
- Not sold individually, please contact us for details

Accessories

- Guide GMC
- Clamps GMC-BR
- Adjusting rod Ø12, Ø14 and Ø16 APB-F

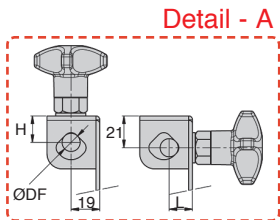

For hostile environments

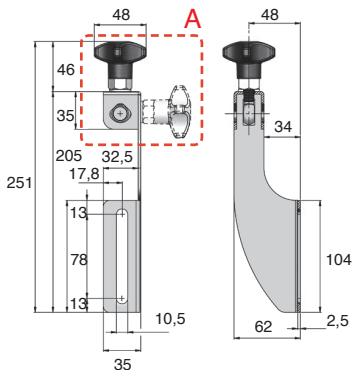

DISCOUNTS

Qty	1+	20+	50+
Disc. List	-5%	On request	

Part number	ØDF	H	L	Weight (kg)	Stock*	Price each 1 to 19
SDG10-UNI/SS	12	18	16	0,33	✓	23,43 €
	14	19	17			
	16	20	19			

*Depending on availability - Dimensions in mm

Our other products



WSSs
Symmetrical S shaped
hook stainless steel,
Stainless steel



PAP
Handle for aluminium
profile, Ergonomic
handle



PF40
Worm and wheel gear
reducer, up to 18 Nm



EML
Stainless steel
hexagonal headed
thumb nut, Lobed
handscrew



PSPE20
Conical flexible shaft
handle Ø20, Black
PVC



PFL
P-FLEX Coupling, Set
screw



GE
Toggle latches,
Miniature



PTGP
Tensioner pulley, For
flat belts



ACLBDB
Closing mechanism
for aluminium profile,
Dual ball catch



SH0
Parallel axis helical
gear, Steel 20NCD2




GSI
Stainless steel gas
spring, Stainless steel



PTA100
Articulated levelling
foot, pressed base
Ø100, Ø 100

 Complementary products



GMC
Flat profile - Round
guide, Flat profile -
round guide



SDG
Adjustable guide
support bracket,
Plastic



APB_F
Adjusting rod for
clamp - Male,
Threaded



APB_T
Adjusting rod for
clamp - Female, Bored