



Universal guide support bracket


Stainless steel

SDGss


- Guide support for bottling and packaging applications
- Materials:
 - reinforced polyamide
 - stainless steel
 - nickel brass (threaded inserts)
- Not sold individually, please contact us for details

Accessories

- Guide GMC
- Clamps GMC-BR
- Adjusting rod Ø12, Ø14 and Ø16 APB-F

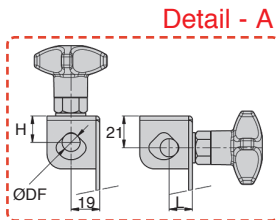

For hostile environments

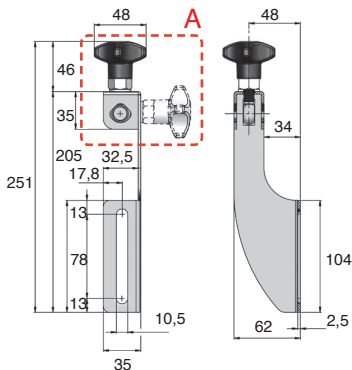

DISCOUNTS

Qty	1+	20+	50+
Disc. List		-5%	On request

Part number	ØDF	H	L	Weight (kg)	Stock*	Price each 1 to 19
SDG10-UNI/SS	12	18	16	0,33	✓	23,43 €
	14	19	17			
	16	20	19			

*Depending on availability - Dimensions in mm

Our other products



CLSCLP
Clevis components,
short version, Steel -
Short range



SAS
Miniature slip friction
clutch, to 8.64 Nm



HLUT
Spoked handwheel
with handle,
Aluminium



AT5P_AT10P
Connecting plate for
AT type timing belts,
AT10



SEH
Horizontal stirrup
toggle clamp,
Horizontal Latch
clamp - stainless ...



UCFL
Cast iron flanged
bearing, Cast iron



CHM63-MOT
Asynchronous AC
motorgearboxes 0.37
to 1.5kW, 0.37 to
1.5kW



NPTF20
Fixed tube carrier,
Fixed Ø10 to Ø14



PLM-20SC
Threaded cylindrical
magnet, With



BLHT60
Right angled gearbox,
from 26 to 70 Nm

 


T5M T10M
T type timing belt per
metre, T10 Steel



ZBconique
Machined plastic
bevel gear, 1:1

Complementary products



GMC
Flat profile - Round
guide, Flat profile -
round guide



SDG
Adjustable guide
support bracket,
Plastic



APB_F
Adjusting rod for
clamp - Male,
Threaded



APB_T
Adjusting rod for
clamp - Female, Bored