

# Magnetic doorstop




 

## SER

## Plastic

- Element for square tube structure
- With adjustable magnet
- Material:  
Body: reinforced polyamide

### Accessories

- Manual lock **LOQ**
- Hinge **CHA**
- Doorstop **BLOC**

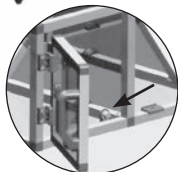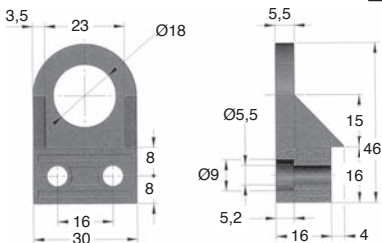

Typical application

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Weight (kg)	Stock*	Price each 1 to 49
SER-MAGNE	0,6	✓	17,35 €

\*Depending on availability - Dimensions in mm

## Our other products



GCH

Linear ball slide -  
Stainless steel balls,  
Chariot - from 514 N  
to 1...



BLHM40

Right angled gearbox,  
double output shafts,  
up to 10.3 Nm



 
RFVcap

Stainless steel  
protective cover,  
Closed protective  
cover



CFF\_SS

Female rod ends DIN  
ISO12240-4, Stainless  
steel / bronze -  
Economy r...



PRZ

Wear strip for slat top  
chain, Z profile to be  
clipped



ERT

Sliding nut, For T slot



RFK38C

Hypoid gearbox -  
Stainless steel, up to  
200 Nm



SVR15

Screwjack with  
travelling nut, with  
moving nut



CLASS

Stainless steel  
indexing handle -  
female, Stainless steel



HG8-ECO

Eco range Spur gear,  
Steel C45



VDSQCB

Sliding lock  
adjustment system,  
Blocking wedge



UGH16

H Type Guide units,  
For Ø12 and Ø16  
actuators

## Complementary products



BLOC

Doorstop, Doorstop



CHA135

Screwed hinge, 135  
degrees