

Quarter turn latch for **the food industry**




Key

SER69K

- Key for SER69K stainless steel 1/4 turn latch
- 2 versions:
Clé-T in plastic with triangular head
Clé-R in plastic with stainless steel insert, rounded head

Advantages

- Ideal for use in the food industry

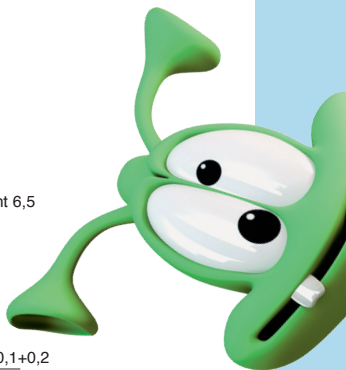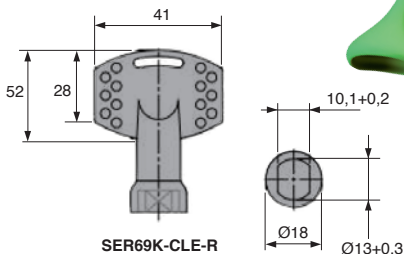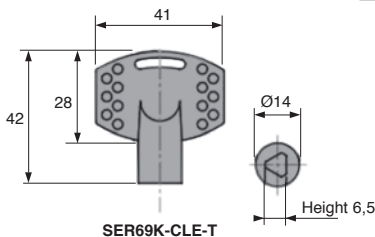

DISCOUNTS

Qty	1+	6+	10+	15+
Disc. List	-5%	-10%	On request	

Part number	Drive	Material	Price each 1 to 5
SER69K-CLE/T	Triangular	Plastic	2,48 €
SER69K-CLE/R	Rounded	Plastic, stainless steel insert	6,25 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC SUPPLEMENT 2019

 
77

Our other products



ACL-PL

Joining plate for aluminium profile, joint plate - 86x86 mm



BMF

Knurled knob - female, Knurled - through threaded



HW_HT

Half-rail guide, Wheel



ABL100000

Antistatic brush, For sensitive surfaces



BOX-TOR-B

Box set of Nitrile O-rings in nitrile, 20.38 x 1.78mm to 50.16 x 5.34



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



STRIPF

Sealing brush strip, 1m length



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



CHAU

Screwed hinge, 270°



SH4

Parallel axis helical gear, Steel 20NCD2



E50

Right angle helical reducers, from 3 to 41



TPEF

Castor for aluminium profile, Fixed

Complementary products



SER69K

Quarter turn latch for the food industry, Stainless steel