

# Quarter turn latch for **the food industry**




Key

SER69K

- Key for SER69K stainless steel 1/4 turn latch
- 2 versions:  
Clé-T in plastic with triangular head  
Clé-R in plastic with stainless steel insert,  
rounded head

## Advantages

- Ideal for use in the food industry

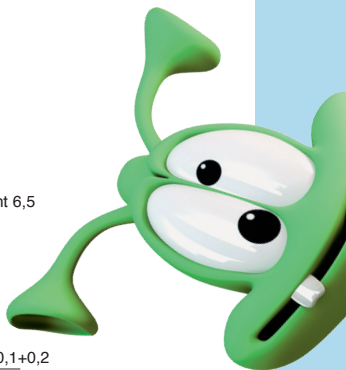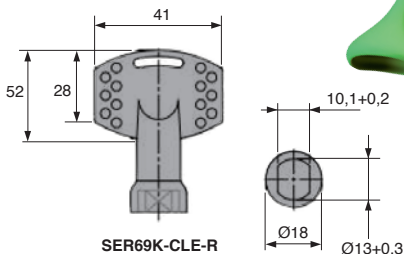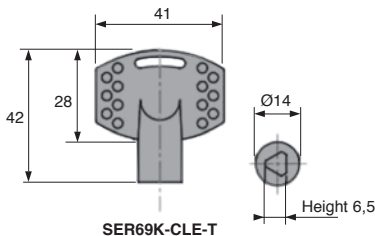

## DISCOUNTS

Qty	1+	6+	10+	15+
Disc. List	-5%	-10%	On request	

Part number	Drive	Material	Price each 1 to 5
SER69K-CLE/T	Triangular	Plastic	2,48 €
SER69K-CLE/R	Rounded	Plastic, stainless steel insert	6,25 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

**HPC** SUPPLEMENT 2019

77

## Our other products



E40

Right angle helical reducers, from 2.30 to 20 Nm




PSG125S

Spur gear - precision range, Stainless steel 303



P45

Worm and wheel gear reducer, up to 40 Nm

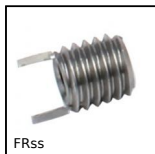

FRss

Stainless steel thread inserts, Stainless steel



PTA80

Articulated levelling foot, pressed base Ø80, Ø 80



B3PAN

Panamech, Multi-Beam stainless steel, Stainless steel - with clampin...



 
RTN

BoWex® curved tooth gear coupling, Nylon



JCSs

Single stainless steel universal joint, Low duty



GMK17\_P

Flat Guide, Flat guide for conical profile



BOX-TOR-ORFS

Box set of Nitrile O-rings NBR90Sh A, 7.65 x 1.78mm to 37.82 x



DKN

Bellows coupling Gerwah®, from 0.4 to 10Nm



SCE\_SS

Stainless steel U-shaped clamp, Stainless steel

## Complementary products



SER69K

Quarter turn latch for the food industry, Stainless steel