

# Quarter turn latch for the food industry



## SER69K

## Stainless steel

- Stainless steel 1/4 turn latch, seal rating IP69K
- Hygienic latch
- Materials:
  - 304 stainless steel
  - O-ring seal, blue silicon




### Advantages

- Ideal for use in the food industry
- No water retaining zones
- Avoids bacteria developing

### Accessories

- See **SER69K-CLE** key

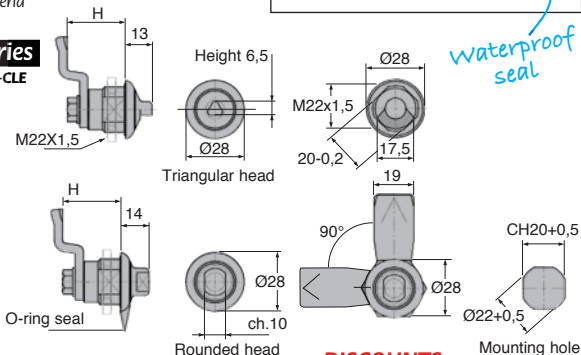

### DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	H	Price each 1 to 5
<b>Triangular head</b>		
SER69K-18/T	18	56,12 €
SER69K-20/T	20	56,12 €
SER69K-22/T	22	56,12 €
SER69K-24/T	24	56,12 €
SER69K-26/T	26	56,12 €
SER69K-28/T	28	56,12 €
<b>Rounded head</b>		
SER69K-18/R	18	56,12 €
SER69K-20/R	20	56,12 €
SER69K-22/R	22	56,12 €
SER69K-24/R	24	56,12 €
SER69K-26/R	26	56,12 €
SER69K-28/R	28	56,12 €

All dimensions in mm

## Our other products



H0

Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



GPB55

Threaded spherical  
knob, Stainless steel  
304



M1

Worm and wheel set,  
Bronze



ASM

Cylindrical polymer  
bush, Food grade  
polymer



UTKpwr

Utilitak® V rail, V rail



AT5P\_AT10P

Connecting plate for  
AT type timing belts,  
AT5




BEAS

Knob star grip  
antistatic, Star, anti-  
static



RFK38C

 Hypoid gearbox -  
Stainless steel, up to  
200 Nm




BH02

Single housed bearing  
assembly, Bearing  
secured with circlips




HTD5M\_15

 HTD Heavy duty  
timing pulley, HTD5  
Aluminium



RPC

 Wheel, Polyamide



EPRF

High helix leadscrew,  
Flanged nut - up to  
40mm per rotation

## Complementary products



SER69K-CLE

Quarter turn latch for  
the food industry,  
Stainless steel key



SERB

Cam latch, Cam latch



LRRss

Latch, Spring loaded  
latch - stainless steel