


# Cam latch

## Hole 8x8

## SERB

- Latch with 3 indexed positions

- Material:  
304 stainless steel  
Natural finish

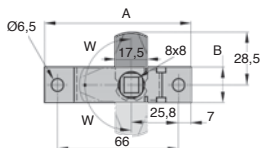

Latch and key



### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List -5%	-10%	On request	

Part number	A	B	C	W	Weight (g)	Price each 1 to 5
SERB80-19/SS	80	19	8	90°	20	20,00 €

Dimensions in mm


# Universal latch key

## For SERB80-19/SS cam latch

## SERB

- Material:

Cast iron

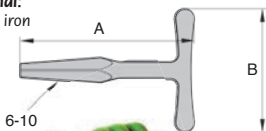

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List -5%	-10%	On request	

Part number	A	B	Weight (g)	Price each 1 to 5
SERB-CLE	90	63,5	58	2,98 €

Dimensions in mm

## Our other products



PDM\_PDV

Detectable plastic palm grip, blue thermoplastic



BABPass

Hardened stainless steel ball pin with ring, With grip ring



LVT

Miniature motorised actuator 4A, 4 ampers



LVT

Miniature motorised actuator 4A, 4 ampers



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



VPSS

Small 6 lobe threaded handle - male, Duroplast - Stainless steel



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



MCL

Cylindrical threaded sleeve, Cylindrical - steel



CHAC4040SS

Square hinge with riveted pin, drilled, Square with riveted



LC

Friction clutch, 30 to 240 Nm



BPPss

Pressed stainless steel pillow block, Stainless steel



PRF4545

Standard stainless steel profile, 45 x 45 mm

## Complementary products



SERB

Universal latch key, Universal latch key



SER69K

Quarter turn latch for the food industry, Stainless steel