

Cam latch

Hole 8x8


SERB

- Latch with 3 indexed positions

- Material:

304 stainless steel

Natural finish

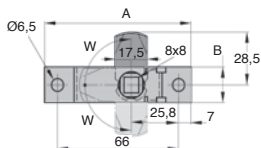

Latch and key



DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	W	Weight (g)	Price each 1 to 5
SERB80-19/SS	80	19	8	90°	20	20,00 €

Dimensions in mm


Universal latch key

For SERB80-19/SS cam latch

SERB

- Material:

Cast iron

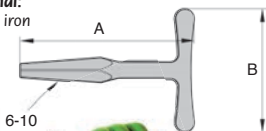

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	Weight (g)	Price each 1 to 5
SERB-CLE	90	63,5	58	2,98 €

Dimensions in mm

Our other products




PGMT
Pull handle, Stainless steel



DOMI120
Domino 120 adjustable slide, Slide DOMILINE 120



 INO
Internal gear, Steel 20NCD2



GMC
Flat profile - Round guide, Flat profile - round guide



SEV
Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel



PHTss
Pull handle, Up to 250 °C



CHA_GC_9SS
Stainless steel garnet hinge, To be welded



STL
Guidance brush - Rail, Rail



PTGT
Tensioner pulley, For V belts



CLSCLP_SS
Clevis components, short version,



BPPE
Ball transfer unit push fit, Light



PM3
Worm and wheel set, Non hardened steel

Complementary products



SERB
Universal latch key, Universal latch key



SER69K
Quarter turn latch for the food industry, Stainless steel