

- 2 materials to choose from
- Materials:
  - SEH** body: zinc plated steel
  - SEH/SS** body: stainless steel 18.9 (303)
  - Handle: Oil-resistant plastic
- Supplied with anchoring base


### Advantages

- Distance of hook from toggle clamp easily adjustable

### Uses

- Designed to secure covers and shutters

Steel or stainless steel

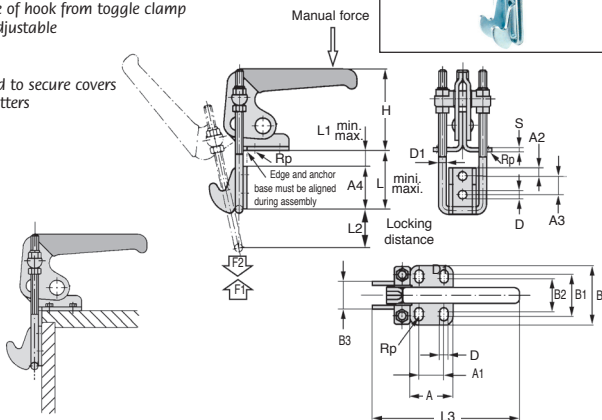

### DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Size	Traction force F1(N)	Pressure F2(N)	Manual force (N)	Opening angle of handle	Adjustable distance L1				Locking distance L2 L3	
					Min.	Max.	Min.	Max.	L2	L3
SEV-01	1800	2000	100	145°	25	49	1	25	22	76
SEV-02	2700	4000	150	145°	33	60	1	28	34	115
SEV-04	4500	7000	200	145°	41	80	1	40	45	152

Part number												Price each 1 to 5					
Steel	Stainless steel	A	A1	A2	A3	A4	B	B1	B2	B3	D	D1	H	S	Steel	StS	
SEV-0140	SEV-0140SS	26	13	4,5	11	24	36	24	19	16	5,2	4	42	2,5	46,34	€ 60,00	€
SEV-0250	SEV-0250SS	35	19	6,0	14	32	48	33	26	21	6,5	6	64	3,0	68,47	€ 84,38	€
SEV-0450	SEV-0450SS	51	32	8,0	19	40	64	45	36	28	8,5	8	85	4,0	114,76	€ 160,18	€

Dimensions in mm


## Our other products



Articulated bracket for use with aluminium profile, Standard




Swivel castor with plate, Stainless steel - Polyamide

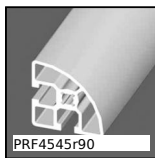

Standard aluminium profile, 45 x 45 mm - R90°



Parallel axis helical gear, Machined plastic (delrin)

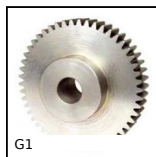

Steel spur gear, Steel 20NCD2



Eco. range steel bevel gear, 1:1




Stainless steel U-shaped clamp, Stainless steel




Machined plastic bevel gear, 2:1



Hexagonal spacer, Brass

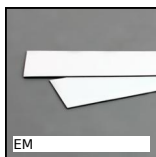

Magnetic label, Flexible magnet

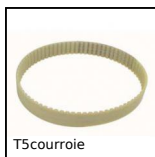

T type timing belt, T5 Steel cored



Articulated foot Ø123, Ø 123

## Complementary products



Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel



Horizontal stirrup toggle clamp, Horizontal stirrup clamp - steel