


- Radial contact ball bearing
- Single row of balls
- With 2 protective shields (ZZ joints)
- Tolerance: P6/ABEC3
- With flange
- Material: stainless steel AISI 440C
- Static and dynamic loads : these bearings can handle approx 70% of the same loads that an equivalent steel bearing will accept
- Max. working temperature: +80°C



stainless steel

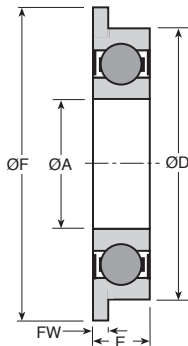

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØA	ØD	E	ØF	FW	Stock*	Price each 1 to 5
SF682ZZ	2,0	5	2,3	6,1	0,6	✓	25,36 €
SF683ZZ	3,0	7	3,0	8,1	0,8	✓	23,48 €
SF684ZZ	4,0	9	4,0	10,3	1,0	✓	23,93 €
SF685ZZ	5,0	11	5,0	12,5	1,0	✓	22,67 €
SF686ZZ	6,0	13	5,0	15,0	1,1	✓	21,75 €
SF687ZZ	7,0	14	5,0	16,0	1,1	✓	23,15 €
SF688ZZ	8,0	16	5,0	18,0	1,1	✓	25,36 €
SF689ZZ	9,0	17	6,0	19,0	1,1	-	24,11 €
SF980ZZ	10,0	19	7,0	21,0	1,5	✓	38,53 €

*Depending on availability - Dimensions in mm

Our other products



PRF_CHA

Hinge for aluminium profile, Surface mounting hinge



EMR

Fast-locking knurled nut, Knurled



PSG055

Spur gear - precision range, Stainless steel 316



HCSS

Set screw with hexagonal socket, Cup point



SR

Narrow spur rack, Stainless steel



PLM-SC

Magnetic stud with central countersunk hole, With milled bore



HFL

One way needle bearing, Needle bearing



P60

Worm and wheel gear reducer, up to 118 Nm



VT

Vari-Tork® slip friction clutch, 0.53 to



VRSSs

Male swivelling lifting rings stainless steel,



DOMI80

Domino 80 adjustable slide, Slide DOMILINE



PRF4590_E

Bracket for aluminium profile, PRF4590

Complementary products



S_ZZ

Deep groove ball bearing, Stainless steel



S_2RS

Deep groove ball bearing, Stainless steel



FUSS

Bearing locknut, Self locking locknut - stainless steel lock washer