


- Radial contact ball bearing
- Single row of balls
- With 2 protective shields (ZZ joints)
- Tolerance: P6/ABEC3
- With flange
- Material: stainless steel AISI 440C
- Static and dynamic loads : these bearings can handle approx 70% of the same loads that an equivalent steel bearing will accept
- Max. working temperature: +80°C



stainless steel

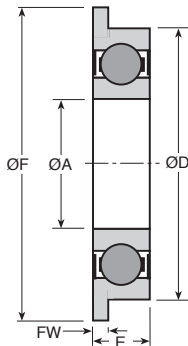

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØA	ØD	E	ØF	FW	Stock*	Price each 1 to 5
SF682ZZ	2,0	5	2,3	6,1	0,6	✓	25,36 €
SF683ZZ	3,0	7	3,0	8,1	0,8	✓	23,48 €
SF684ZZ	4,0	9	4,0	10,3	1,0	✓	23,93 €
SF685ZZ	5,0	11	5,0	12,5	1,0	✓	22,67 €
SF686ZZ	6,0	13	5,0	15,0	1,1	✓	21,75 €
SF687ZZ	7,0	14	5,0	16,0	1,1	✓	23,15 €
SF688ZZ	8,0	16	5,0	18,0	1,1	✓	25,36 €
SF689ZZ	9,0	17	6,0	19,0	1,1	-	24,11 €
SF980ZZ	10,0	19	7,0	21,0	1,5	✓	38,53 €

*Depending on availability - Dimensions in mm

Our other products



BLH60

Right angled gearbox, from 19 to 70 Nm



SGIT

Floor mounting levelling plate, With anchoring point




BLH50

Right angled gearbox, from 7.70 to 20 Nm



PAMF80EB

 Articulated foot with sheet metal base Ø80, Articulated foot



RPP14

RPP heavy duty timing belt, RPP14



UGCG

Actuator guide kit, Long housing



VCMB

Dual-thread screw wood/metal, Stainless steel




MHMEP

Arm with rotating handle, Prebored



PTA150

 Articulated levelling foot, pressed base



RPP

Connecting plate for RPP type timing belts,



OP2

Mechanical digital position indicator, 3



SLB

Indexing plunger, steel class 5.8

Complementary products



S_ZZ

Deep groove ball bearing, Stainless steel



S_2RS

Deep groove ball bearing, Stainless steel



FUSS

Bearing locknut, Self locking locknut - stainless steel lock washer