


- Radial contact ball bearing
- Single row of balls
- With 2 protective shields (ZZ joints)
- Tolerance: P6/ABEC3
- With flange
- Material: stainless steel AISI 440C
- Static and dynamic loads : these bearings can handle approx 70% of the same loads that an equivalent steel bearing will accept
- Max. working temperature: +80°C



stainless steel

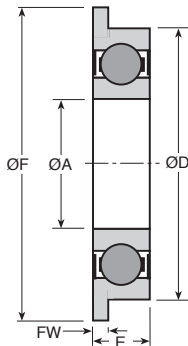

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØA	ØD	E	ØF	FW	Stock*	Price each 1 to 5
SF682ZZ	2,0	5	2,3	6,1	0,6	✓	25,36 €
SF683ZZ	3,0	7	3,0	8,1	0,8	✓	23,48 €
SF684ZZ	4,0	9	4,0	10,3	1,0	✓	23,93 €
SF685ZZ	5,0	11	5,0	12,5	1,0	✓	22,67 €
SF686ZZ	6,0	13	5,0	15,0	1,1	✓	21,75 €
SF687ZZ	7,0	14	5,0	16,0	1,1	✓	23,15 €
SF688ZZ	8,0	16	5,0	18,0	1,1	✓	25,36 €
SF689ZZ	9,0	17	6,0	19,0	1,1	-	24,11 €
SF980ZZ	10,0	19	7,0	21,0	1,5	✓	38,53 €

*Depending on availability - Dimensions in mm

Our other products



SH1

Parallel axis helical gear, Machined plastic (delrin)




NPCR

Adjustable cell support, Adjustable



NPTR

Adjustable cross clamp, Adjustable

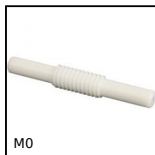

M0

Worm and wheel set, Machined plastic (delrin)



RIMtce

Locking castor, with central hole



MLY_SS

Stainless steel bow shackle with eye bolt, Stainless steel



HG8-ECO

Eco range Spur gear, Steel C45



BIM

Indexing plunger mini, miniature



GAL_20

Conveyor roller for Ø20mm spindle, Self-




PR125rehausse

Extension for articulated foot Ø123,



PP50

 Worm and wheel gear reducer, from 6.50 to



B

Steel bevel gear, 1:1

Complementary products



S_ZZ

Deep groove ball bearing, Stainless steel



S_2RS

Deep groove ball bearing, Stainless steel



FUSS

Bearing locknut, Self locking locknut - stainless steel lock washer