


- Radial contact ball bearing
- Single row of balls
- With 2 protective shields (ZZ joints)
- Tolerance: P6/ABEC3
- With flange
- Material: stainless steel AISI 440C
- Static and dynamic loads : these bearings can handle approx 70% of the same loads that an equivalent steel bearing will accept
- Max. working temperature: +80°C



stainless steel

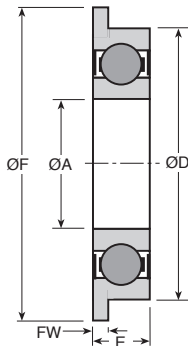

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØA	ØD	E	ØF	FW	Stock*	Price each 1 to 5
SF682ZZ	2,0	5	2,3	6,1	0,6	✓	25,36 €
SF683ZZ	3,0	7	3,0	8,1	0,8	✓	23,48 €
SF684ZZ	4,0	9	4,0	10,3	1,0	✓	23,93 €
SF685ZZ	5,0	11	5,0	12,5	1,0	✓	22,67 €
SF686ZZ	6,0	13	5,0	15,0	1,1	✓	21,75 €
SF687ZZ	7,0	14	5,0	16,0	1,1	✓	23,15 €
SF688ZZ	8,0	16	5,0	18,0	1,1	✓	25,36 €
SF689ZZ	9,0	17	6,0	19,0	1,1	-	24,11 €
SF980ZZ	10,0	19	7,0	21,0	1,5	✓	38,53 €

*Depending on availability - Dimensions in mm

Our other products



AT10-25ECO

AT type timing pulley,
Economy range -
AT10 aluminium



RFK38C

Hypoid gearbox -
Stainless steel, up to
200 Nm



NTM

Nylon tipped set
screw, Nylon-point



PLA

Flat magnet, Flat
magnet



BPH

Ball transfer unit plain
fit, High



BDPR

Holding arm, Rigid



RCC_RCX

Spherical tilt washer -
DIN6319, convex



RDERSS

Stainless steel manual
rigging screw,
Stainless steel -
manual



SH2

Parallel axis helical
gear, Machined plastic
(delrin)



CHAR5050_Z

Spring hinge, screwed



CDC

Conical compression
spring, Conical



NT62

Spur gear coaxial
gearbox, from 6 to 18
Nm - In-line

Complementary products



S_ZZ

Deep groove ball
bearing, Stainless
steel



S_2RS

Deep groove ball
bearing, Stainless
steel



FUSS

Bearing locknut, Self
locking locknut -
stainless steel lock
washer