


- Radial contact ball bearing
- Single row of balls
- With 2 protective shields (ZZ joints)
- Tolerance: P6/ABEC3
- With flange
- Material: stainless steel AISI 440C
- Static and dynamic loads : these bearings can handle approx 70% of the same loads that an equivalent steel bearing will accept
- Max. working temperature: +80°C

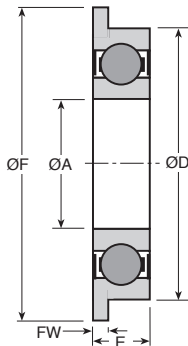

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØA	ØD	E	ØF	FW	Stock*	Price each 1 to 5
SF682ZZ	2,0	5	2,3	6,1	0,6	✓	25,36 €
SF683ZZ	3,0	7	3,0	8,1	0,8	✓	23,48 €
SF684ZZ	4,0	9	4,0	10,3	1,0	✓	23,93 €
SF685ZZ	5,0	11	5,0	12,5	1,0	✓	22,67 €
SF686ZZ	6,0	13	5,0	15,0	1,1	✓	21,75 €
SF687ZZ	7,0	14	5,0	16,0	1,1	✓	23,15 €
SF688ZZ	8,0	16	5,0	18,0	1,1	✓	25,36 €
SF689ZZ	9,0	17	6,0	19,0	1,1	-	24,11 €
SF980ZZ	10,0	19	7,0	21,0	1,5	✓	38,53 €

*Depending on availability - Dimensions in mm

Our other products




MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



TBEBASE10

Economic mini-table with trapezoidal lead screw, 1kg

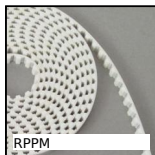

RPPM

RPP type belt per metre, RPP14 Steel cored polyurethane



DOMI50

Connecting kits, XZ linking kit



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



CQA30

Accessory for adjustment slide system, 30



DB

Steel bevel gear, 2:1



SUA4

Single chain supplied by the metre, Steel



RFK28C

Hypoid gearbox - Stainless steel, up to 130 Nm



CAP882

Flexible slat top chain acetal, Large range 882



E60

Right angle helical reducers, from 4.50 to 62 Nm



RPP

Connecting plate for RPP type timing belts, RPP8

Complementary products



S_ZZ

Deep groove ball bearing, Stainless steel



S_2RS

Deep groove ball bearing, Stainless steel



FUSS

Bearing locknut, Self locking locknut - stainless steel lock washer