
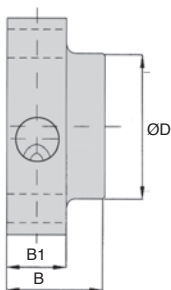


- For linear guide shaft
- End support bracket
- Material: Aluminium
- Adjustable backlash
- Mounting holes conform to DIN912 8.8

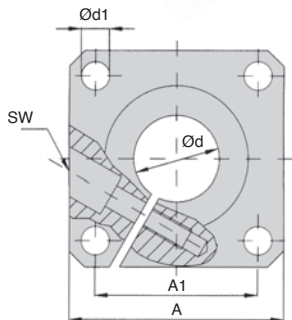


DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	Ød	A	B	ØD	A1	Ød1	B1	SW	Weight (kg)	Stock*	Price each 1 to 4
SFWR-12	12	40	20	23,5	30 ^{+0,12}	5,5	12	M3	0,05	✓	50,59 €
SFWR-16	16	50	20	27,5	35 ^{+0,12}	5,5	12	M3	0,08	✓	57,54 €
SFWR-20	20	50	23	33,5	38 ^{+0,15}	6,6	14	M4	0,10	✓	64,49 €
SFWR-25	25	60	25	42,0	42 ^{+0,15}	6,6	16	M5	0,15	✓	73,44 €
SFWR-30	30	70	30	49,5	54 ^{+0,25}	9,0	19	M6	0,24	✓	94,28 €
SFWR-40	40	100	40	65,0	68 ^{+0,25}	11,0	26	M8	0,66	✓	114,14 €
SFWR-50	50	100	50	75,0	75 ^{+0,25}	11,0	36	M8	0,82	-	154,46 €

*Depending on availability - Dimensions in mm

 Our other products



TCXR

Automatic chain tensioner, With stainless steel sprocket



SLB

Indexing plunger, stainless steel



GTCSS

Belt tensioner, For use in hostile environments



MEB

Moulded plastic bevel gear (nylon), 1:1



BH02

Single housed bearing assembly, Bearing secured with circlips



WJRM

Drylin® W hybrid bearing block, Hybrid bearings



PSG055

Spur gear - precision range, Stainless steel 303



R205

Die spring ISO10243, Heavy



BPM-Z

Plastic slotted spring plunger with ball tip,



BOX-TOR-A

Box set of Nitrile O-rings in nitrile, 2.90 x



YG0

HEAVY DUTY spur gear, Steel 35NCD6



BAG-MI

Split shaft collar with clamp lever, Steel

Complementary products



ZA

Shaft for linear guides, Hardened ground steel



ZB

Shaft for linear guides, Hardened ground stainless steel



ZA

Shaft for linear guides, Hardened ground steel



AWMP

Aluminium shaft for linear guide, Aluminium