


- For linear guide shaft
- End support bracket
- Material: Aluminium
- Adjustable backlash
- Mounting holes conform to DIN912 8.8

### Accessories

- Linear shaft
- Z-A (vol. 1 p.246)
- Z-B (vol. 1 p.247)

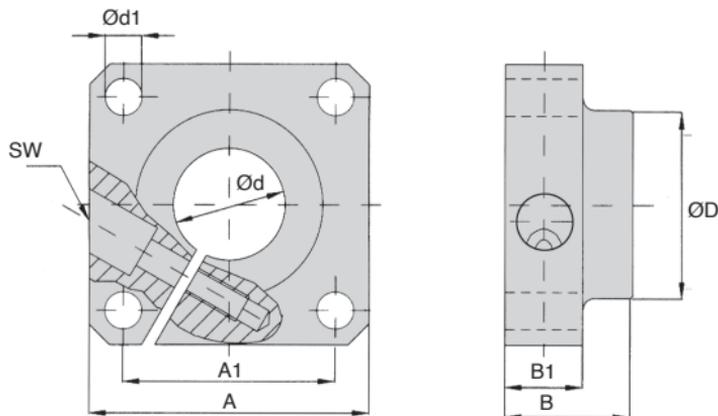

### DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request



Part number	Ød	A	B	ØD	A1	Ød1	B1	SW	Weight (kg)	Stock*	Price each 1 to 4
SFWR-12	12	40	20	23,5	30 <sup>+0,12</sup>	5,5	12	M3	0,05	✓	56,43 €
SFWR-16	16	50	20	27,5	35 <sup>+0,12</sup>	5,5	12	M3	0,08	✓	64,21 €
SFWR-20	20	50	23	33,5	38 <sup>+0,15</sup>	6,6	14	M4	0,10	✓	71,97 €
SFWR-25	25	60	25	42,0	42 <sup>+0,15</sup>	6,6	16	M5	0,15	✓	81,95 €
SFWR-30	30	70	30	49,5	54 <sup>+0,25</sup>	9,0	19	M6	0,24	✓	105,21 €
SFWR-40	40	100	40	65,0	68 <sup>+0,25</sup>	11,0	26	M8	0,66	✓	127,37 €
SFWR-50	50	100	50	75,0	75 <sup>+0,25</sup>	11,0	36	M8	0,82	-	172,40 €

\*Depending on availability - Dimensions in mm

- End support for linear guide shaft
- Material: Aluminium
- Adjustable backlash
- Mounting holes conform to DIN912 8.8

### Accessories

- Ground shafts
- Z-A (tome 3 p.246)
- Z-B (tome 3 p.247)

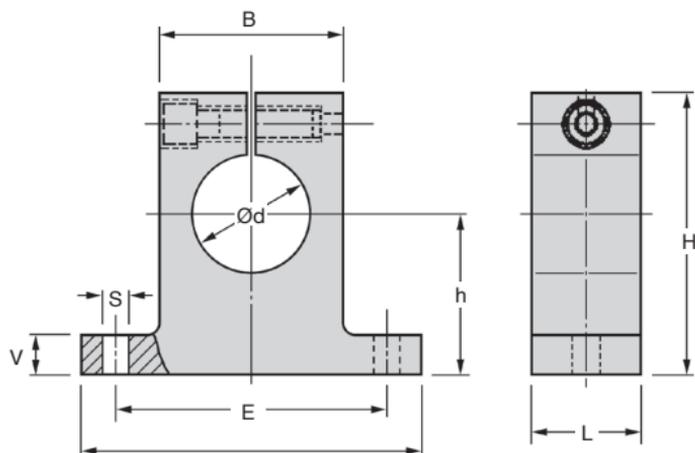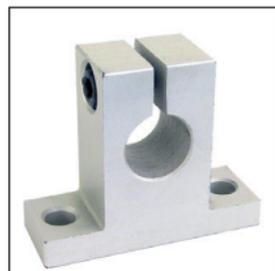

### DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	Ød	h	B	H	L	A	S	V	E	Stock*	Price each 1 to 4
FGWA-12	12	20	20	35	12	42	5,5	5,5	32	✓	15,27 €
FGWA-16	16	25	26	42	15	50	5,5	6,5	40	✓	16,99 €
FGWA-20	20	30	32	50	20	60	5,5	8,0	45	✓	21,24 €
FGWA-25	25	35	38	58	25	74	6,6	9,0	60	✓	24,21 €
FGWA-30	30	40	45	68	30	84	9,0	10,0	68	✓	37,43 €
FGWA-40	40	50	56	86	30	108	11,0	12,0	86	✓	71,52 €
FGWA-50	50	60	80	100	40	130	11,0	14,0	108	-	110,66 €

\*Depending on availability - Dimensions in mm