
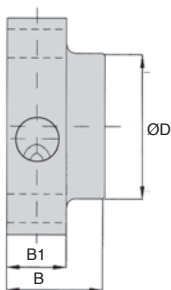


- For linear guide shaft
- End support bracket
- Material: Aluminium
- Adjustable backlash
- Mounting holes conform to DIN912 8.8

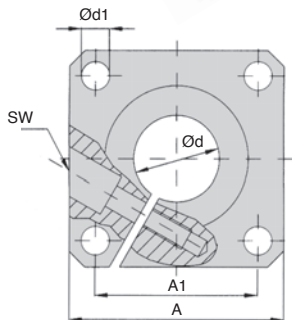

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	Ød	A	B	ØD	A1	Ød1	B1	SW	Weight (kg)	Stock*	Price each 1 to 4
SFWR-12	12	40	20	23,5	30 ^{+0,12}	5,5	12	M3	0,05	✓	50,59 €
SFWR-16	16	50	20	27,5	35 ^{+0,12}	5,5	12	M3	0,08	✓	57,54 €
SFWR-20	20	50	23	33,5	38 ^{+0,15}	6,6	14	M4	0,10	✓	64,49 €
SFWR-25	25	60	25	42,0	42 ^{+0,15}	6,6	16	M5	0,15	✓	73,44 €
SFWR-30	30	70	30	49,5	54 ^{+0,25}	9,0	19	M6	0,24	✓	94,28 €
SFWR-40	40	100	40	65,0	68 ^{+0,25}	11,0	26	M8	0,66	✓	114,14 €
SFWR-50	50	100	50	75,0	75 ^{+0,25}	11,0	36	M8	0,82	-	154,46 €

 
*Depending on availability - Dimensions in mm

Our other products



SUPss

Self-centering clamping hub stainless steel, Without locknut



VAB

Ballscrew, supplied by the metre, Rolled ballscrew, per metre



YG1

HEAVY DUTY spur gear, Steel 35NCD6



RFV63

Stainless steel worm and wheel gearbox, up to 152 Nm



DOG319

Motor-gearbox 12V and 24V DC, from 4 to 9 Nm



PDM_PDV

Detectable plastic palm grip, by metal detectors




BLH20

Right angled gearbox, from 0.53 to 1.77



ACL-PLAngle

 Joining plate for aluminium profile, Angle connection



PRT-TO

igidur® slewing ring, With external teeth-igidur®, aluminium &



SSDB

Stainless steel bevel gear, 2:1



PPF

Indexing plunger with flange, with drilled flange



PSG15

Spur gear - precision range, Pre-hardened Steel 35NCD6

Complementary products



ZA

Shaft for linear guides, Hardened ground steel



ZB

Shaft for linear guides, Hardened ground stainless steel



ZA

Shaft for linear guides, Hardened ground steel



AWMP

Aluminium shaft for linear guide, Aluminium