


Parallel axis helical gear



Module 0.7

Steel or **machined** plastic

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

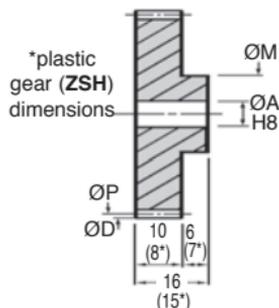

Info.

Important: a right handed gear only meshes with a left handed gear.

Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc. List	-12%	-25%	On request	

Plastic DISCOUNTS

Qty	1+	6+	30+
Disc. List	-22%	On request	

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	delrin
Nm	1.73	6.83	0.86	0.4
kW	0.18	0.72	0.09	-

Part number	Z	ØP PCD	ØD Outside	ØM Boss		ØA Bore		Price each 1 to 5		
				SH	ZSH	SH	ZSH	SH	ZSH	
Steel	Plastic	Teeth								
SH0.7-10	-	10	7.35	8.75	8.75	-	4	-	20,18 €	-
SH0.7-11	-	11	8.09	9.49	9.49	-	5	-	20,18 €	-
SH0.7-15	ZSH0.7-15	15	11.03	12.43	11.90	12.43	5	3	21,55 €	10,79 €
SH0.7-20	ZSH0.7-20	20	14.70	16.10	12.00	12.00	5	3	23,81 €	11,89 €
SH0.7-22	ZSH0.7-22	22	16.17	17.57	12.00	12.00	5	3	24,27 €	12,19 €
SH0.7-25	ZSH0.7-25	25	18.38	19.78	12.00	14.00	5	4	25,01 €	12,57 €
SH0.7-30	ZSH0.7-30	30	22.05	23.45	12.00	14.00	5	4	25,93 €	12,98 €
SH0.7-34	ZSH0.7-34	34	24.99	26.39	16.00	14.00	6	4	26,27 €	13,19 €
SH0.7-35	ZSH0.7-35	35	25.73	27.13	16.00	14.00	6	4	26,33 €	13,19 €
SH0.7-40	ZSH0.7-40	40	29.40	30.80	16.00	16.00	6	5	26,60 €	14,69 €
SH0.7-45	ZSH0.7-45	45	33.08	34.48	16.00	16.00	6	5	26,87 €	14,87 €
SH0.7-50	ZSH0.7-50	50	36.75	38.15	16.00	16.00	6	5	27,47 €	15,22 €
SH0.7-51	ZSH0.7-51	51	37.49	38.89	16.00	16.00	6	5	27,58 €	15,22 €
SH0.7-55	ZSH0.7-55	55	40.43	41.83	16.00	16.00	6	5	28,10 €	17,66 €
SH0.7-60	ZSH0.7-60	60	44.10	45.50	16.00	16.00	6	5	28,77 €	18,07 €
SH0.7-70	ZSH0.7-70	70	51.45	52.85	16.00	18.00	8	6	29,94 €	22,57 €
SH0.7-75	ZSH0.7-75	75	55.13	56.63	16.00	18.00	8	6	30,57 €	23,13 €
SH0.7-80	ZSH0.7-80	80	58.80	60.20	16.00	18.00	8	6	31,88 €	27,33 €
SH0.7-90	ZSH0.7-90	90	66.15	67.55	16.00	18.00	8	6	33,69 €	28,85 €
SH0.7-100	ZSH0.7-100	100	73.50	74.90	16.00	18.00	8	6	42,84 €	36,72 €
SH0.7-120	ZSH0.7-120	120	88.20	89.60	20.00	18.00	8	8	58,49 €	53,11 €
SH0.7-140	-	140	102.63	104.30	20.00	-	10	-	66,65 €	-
SH0.7-150	-	150	110.25	111.65	25.00	-	10	-	72,27 €	-
SH0.7-175	-	175	128.63	130.03	30.00	-	15	-	83,30 €	-

Gears available up to this size

SH0.7-188	ZSH0.7-188	188	Dimensions: contact us				On request	On request
-----------	------------	-----	------------------------	--	--	--	------------	------------

Dimensions in mm

Our other products



BAC105

Storage bin, 8mm



gt64r

Rotating bent lever with spring, Increased fitting tolerances




GMK17_RG

Joint for guiding profile, Rounded



NPTR_M

Adjustable cross clamp, Adjustable

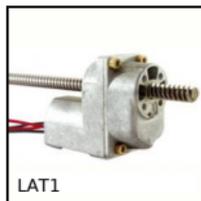

LAT1

1A motorised linear actuator, 1 ampere




PRESSHR

Manual workbench press, Force up to 500kg




BPPEBLU

Ball transfer unit in blue certified plastic, for foodstuff sector

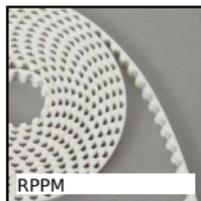

RPPM

RPP type belt per metre, RPP14 Steel cored polyurethane

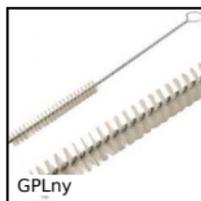

GPLny

Brush, nylon



PGT

Sliding profile, Sliding panel support



GE1006

Elastic ringed latch, Hooks into a slot



BFM2

Flanged bronze nut, Bronze - 2 threads

Complementary products



SH0

Parallel axis helical gear, Steel 20NCD2