
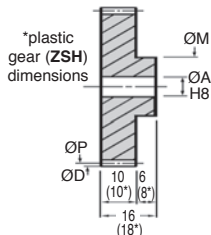


- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

### Info.

**Important:** a right handed gear only meshes with a left handed gear.

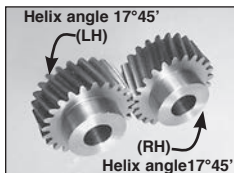

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 ZiOCNF18.09	20NCD2 hardened	brass	delrin
Nm	2.25	8.92	1.13	0.5
kW	0.24	0.93	0.12	-

### Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

### Plastic DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Z	Teeth	PCD	ØD Outside	ØM Boss SH	ZSH	ØA Bore		Price each 1 to 5
							SH	ZSH	
SH0.8-10	-	10	8,40	10,00	10	-	5	-	20,18 € -
SH0.8-15	ZSH0.8-15	15	12,60	14,20	12	14,20	5	3	21,55 € 10,79 €
SH0.8-16	ZSH0.8-16	16	13,44	15,04	12	15,04	5	3	22,11 € 11,04 €
SH0.8-19	ZSH0.8-19	19	15,96	17,56	12	14,00	5	4	23,52 € 11,76 €
SH0.8-20	ZSH0.8-20	20	16,80	18,40	12	14,00	5	4	23,81 € 11,89 €
SH0.8-25	ZSH0.8-25	25	21,00	22,60	12	14,00	5	4	25,01 € 12,57 €
SH0.8-28	ZSH0.8-28	28	23,52	25,12	12	14,00	5	4	25,65 € 12,85 €
SH0.8-30	ZSH0.8-30	30	25,20	26,80	16	16,00	6	5	25,93 € 12,98 €
SH0.8-35	ZSH0.8-35	35	29,40	31,00	16	16,00	6	5	26,33 € 14,52 €
SH0.8-40	ZSH0.8-40	40	33,60	35,20	16	16,00	6	5	26,60 € 14,69 €
SH0.8-45	ZSH0.8-45	45	37,80	39,40	16	16,00	6	5	26,87 € 14,87 €
SH0.8-50	ZSH0.8-50	50	42,00	43,60	16	16,00	6	5	27,30 € 17,13 €
SH0.8-55	ZSH0.8-55	55	46,20	47,80	16	18,00	6	6	27,99 € 17,62 €
SH0.8-60	ZSH0.8-60	60	50,40	52,00	16	18,00	8	6	28,46 € 21,51 €
SH0.8-66	ZSH0.8-66	66	55,44	57,04	16	18,00	8	6	29,17 € 21,97 €
SH0.8-70	ZSH0.8-70	70	58,80	60,40	16	18,00	8	6	29,42 € 25,20 €
SH0.8-75	ZSH0.8-75	75	63,00	64,60	16	18,00	8	6	29,94 € 25,65 €
SH0.8-80	ZSH0.8-80	80	67,20	68,80	16	18,00	8	6	31,44 € 26,92 €
SH0.8-90	ZSH0.8-90	90	75,60	77,20	20	22,00	8	6	33,16 € 30,05 €
SH0.8-100	ZSH0.8-100	100	84,00	85,60	20	22,00	8	8	36,89 € 33,52 €
SH0.8-120	ZSH0.8-120	120	100,80	102,40	20	30,00	10	10	48,72 € 54,09 €
SH0.8-140	ZSH0.8-140	140	117,60	119,20	20	30,00	10	10	63,81 € 67,79 €
SH0.8-150	-	150	126,00	127,60	30	-	12	-	73,76 € -

### Gears available up to this size

SH0.8-164	ZSH0.8-164	164	Dimensions: contact us		On request	On request
-----------	------------	-----	------------------------	--	------------	------------

Dimensions in mm

## Our other products



UTKpwrr  
V shaped channel  
UtiliTrak®, V rail



MBEX  
Hexagonal ended  
handle, Hexagonal  
ended handle



KB\_OP  
Open precision linear  
bearing, Precision -  
steel




DOMI120  
Domino 120  
adjustable slide, Slide  
DOMILINE 120



ACL-FPA  
Panel mounting block  
for aluminium  
structures, Support  
block



 CHML63  
Worm and wheel gear  
reducer, up to 138  
Nm - Integrated  
torque limiter



T5\_11  
T type timing pulley,  
T5 aluminium



EMAS  
Antistatic knurled nut,  
Antistatic



PPC55  
Pad eye on mounting  
plate squarred,



CHINV  
Invisible hinge,  
Invisible - Opening up



BPLF  
Ball transfer unit light  
duty, Light



LVT  
Miniature motorised  
actuator 2A, 2 ampers

## Complementary products



SH0  
Parallel axis helical  
gear, Machined plastic  
(delrin)