


- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

### Info.

**Important:** a right handed gear only meshes with a left handed gear.

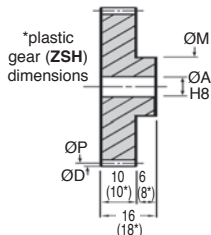

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 ZiOCNF18.09	20NCD2 hardened	brass	delrin
Nm	2.25	8.92	1.13	0.5
kW	0.24	0.93	0.12	-

### Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

### Plastic DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Steel	Plastic	Z Teeth	ØP PCD	ØD Outside	ØM Boss		ØA Bore		Price each 1 to 5	
						SH	ZSH	SH	ZSH	SH	ZSH
SH0.8-10	-		10	8,40	10,00	10	-	5	-	20,18 €	-
SH0.8-15	ZSH0.8-15		15	12,60	14,20	12	14,20	5	3	21,55 €	10,79 €
SH0.8-16	ZSH0.8-16		16	13,44	15,04	12	15,04	5	3	22,11 €	11,04 €
SH0.8-19	ZSH0.8-19		19	15,96	17,56	12	14,00	5	4	23,52 €	11,76 €
SH0.8-20	ZSH0.8-20		20	16,80	18,40	12	14,00	5	4	23,81 €	11,89 €
SH0.8-25	ZSH0.8-25		25	21,00	22,60	12	14,00	5	4	25,01 €	12,57 €
SH0.8-28	ZSH0.8-28		28	23,52	25,12	12	14,00	5	4	25,65 €	12,85 €
SH0.8-30	ZSH0.8-30		30	25,20	26,80	16	16,00	6	5	25,93 €	12,98 €
SH0.8-35	ZSH0.8-35		35	29,40	31,00	16	16,00	6	5	26,33 €	14,52 €
SH0.8-40	ZSH0.8-40		40	33,60	35,20	16	16,00	6	5	26,60 €	14,69 €
SH0.8-45	ZSH0.8-45		45	37,80	39,40	16	16,00	6	5	26,87 €	14,87 €
SH0.8-50	ZSH0.8-50		50	42,00	43,60	16	16,00	6	5	27,30 €	17,13 €
SH0.8-55	ZSH0.8-55		55	46,20	47,80	16	18,00	6	6	27,99 €	17,62 €
SH0.8-60	ZSH0.8-60		60	50,40	52,00	16	18,00	8	6	28,46 €	21,51 €
SH0.8-66	ZSH0.8-66		66	55,44	57,04	16	18,00	8	6	29,17 €	21,97 €
SH0.8-70	ZSH0.8-70		70	58,80	60,40	16	18,00	8	6	29,42 €	25,20 €
SH0.8-75	ZSH0.8-75		75	63,00	64,60	16	18,00	8	6	29,94 €	25,65 €
SH0.8-80	ZSH0.8-80		80	67,20	68,80	16	18,00	8	6	31,44 €	26,92 €
SH0.8-90	ZSH0.8-90		90	75,60	77,20	20	22,00	8	6	33,16 €	30,05 €
SH0.8-100	ZSH0.8-100		100	84,00	85,60	20	22,00	8	8	36,89 €	33,52 €
SH0.8-120	ZSH0.8-120		120	100,80	102,40	20	30,00	10	10	48,72 €	54,09 €
SH0.8-140	ZSH0.8-140		140	117,60	119,20	20	30,00	10	10	63,81 €	67,79 €
SH0.8-150	-		150	126,00	127,60	30	-	12	-	73,76 €	-

### Gears available up to this size


SH0.8-164	ZSH0.8-164	164	Dimensions: contact us	On request	On request
-----------	------------	-----	------------------------	------------	------------

Dimensions in mm

## Our other products



 PTA100  
Articulated levelling  
foot, pressed base  
Ø100, Ø 100




RPP5  
RPP heavy duty  
timing belt, RPP5



PSG055  
Spur gear - precision  
range, Stainless steel  
303



 TCL-ECL  
Adjusting nut, Fine  
thread



RPP  
Connecting plate for  
RPP type timing belts,  
RPP14



JSM  
Cylindrical polymer  
bush, Universal  
polymer



RPP  
Connecting plate for  
RPP type timing belts,  
RPP8



HLUMss  
Revolving handle for  
handwheel, Stainless  
steel 316



RPP  
Connecting plate for  
RPP type timing belts,  
RPP5



BAN  
Angular clamp,  
Standard



H0  
Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



VQT  
Quarter-turn clamp  
lock, Plastic or  
stainless steel button

## Complementary products



SH0  
Parallel axis helical  
gear, Steel 20NCD2