
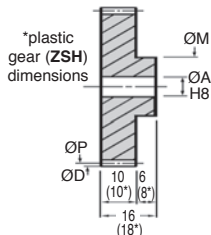


- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

Info.

Important: a right handed gear only meshes with a left handed gear.

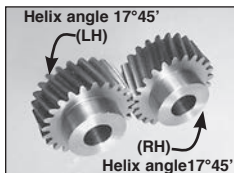

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	delrin
Nm	2.25	8.92	1.13	0.5
kW	0.24	0.93	0.12	-

Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Plastic DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Steel	Plastic	Z Teeth	ØP PCD	ØD Outside	ØM Boss		ØA Bore		Price each 1 to 5	
						SH	ZSH	SH	ZSH	SH	ZSH
SH0.8-10	-		10	8,40	10,00	10	-	5	-	20,18 €	-
SH0.8-15	ZSH0.8-15		15	12,60	14,20	12	14,20	5	3	21,55 €	10,79 €
SH0.8-16	ZSH0.8-16		16	13,44	15,04	12	15,04	5	3	22,11 €	11,04 €
SH0.8-19	ZSH0.8-19		19	15,96	17,56	12	14,00	5	4	23,52 €	11,76 €
SH0.8-20	ZSH0.8-20		20	16,80	18,40	12	14,00	5	4	23,81 €	11,89 €
SH0.8-25	ZSH0.8-25		25	21,00	22,60	12	14,00	5	4	25,01 €	12,57 €
SH0.8-28	ZSH0.8-28		28	23,52	25,12	12	14,00	5	4	25,65 €	12,85 €
SH0.8-30	ZSH0.8-30		30	25,20	26,80	16	16,00	6	5	25,93 €	12,98 €
SH0.8-35	ZSH0.8-35		35	29,40	31,00	16	16,00	6	5	26,33 €	14,52 €
SH0.8-40	ZSH0.8-40		40	33,60	35,20	16	16,00	6	5	26,60 €	14,69 €
SH0.8-45	ZSH0.8-45		45	37,80	39,40	16	16,00	6	5	26,87 €	14,87 €
SH0.8-50	ZSH0.8-50		50	42,00	43,60	16	16,00	6	5	27,30 €	17,13 €
SH0.8-55	ZSH0.8-55		55	46,20	47,80	16	18,00	6	6	27,99 €	17,62 €
SH0.8-60	ZSH0.8-60		60	50,40	52,00	16	18,00	8	6	28,46 €	21,51 €
SH0.8-66	ZSH0.8-66		66	55,44	57,04	16	18,00	8	6	29,17 €	21,97 €
SH0.8-70	ZSH0.8-70		70	58,80	60,40	16	18,00	8	6	29,42 €	25,20 €
SH0.8-75	ZSH0.8-75		75	63,00	64,60	16	18,00	8	6	29,94 €	25,65 €
SH0.8-80	ZSH0.8-80		80	67,20	68,80	16	18,00	8	6	31,44 €	26,92 €
SH0.8-90	ZSH0.8-90		90	75,60	77,20	20	22,00	8	6	33,16 €	30,05 €
SH0.8-100	ZSH0.8-100		100	84,00	85,60	20	22,00	8	8	36,89 €	33,52 €
SH0.8-120	ZSH0.8-120		120	100,80	102,40	20	30,00	10	10	48,72 €	54,09 €
SH0.8-140	ZSH0.8-140		140	117,60	119,20	20	30,00	10	10	63,81 €	67,79 €
SH0.8-150	-		150	126,00	127,60	30	-	12	-	73,76 €	-

Gears available up to this size

SH0.8-164	ZSH0.8-164	164	Dimensions: contact us	On request	On request
-----------	------------	-----	------------------------	------------	------------

Dimensions in mm

Our other products



JSM

Cylindrical polymer bush, Universal polymer



gt64r

Rotating bent lever with spring, Increased fitting tolerances



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



NKXR

Combined bearing without inner ring, Needle and cylindrical rollers



GGP

Male wing knob, Technopolymer with stainless steel spindle



DER63

Stainless steel AC asynchronous motor 0.18 kW, 0.18kW



ADL_F

Female eye bolt conforms to DIN582, Stainless steel



CFUURSS

Cam follower stainless steel, Standard - stainless steel



AC144

Strike for toggle latch, 22mm



RTE

Rotex®, jaw coupling, steel



ACLPP

Latch for aluminium profile, Spring operated latch



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane

Complementary products



SH0

Parallel axis helical gear, Steel 20NCD2