



Steel or machined plastic

Module 0.8

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

Info.

Important: a right handed gear only meshes with a left handed gear.

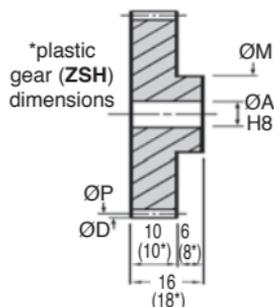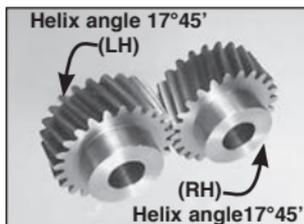

Torque and power indication

For 50 teeth at 1000 rpm

	20NCD2 ZiOCNF18.09	20NCD2 hardened	brass	delrin
Nm	2.25	8.92	1.13	0.5
kW	0.24	0.93	0.12	-

Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Plastic DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request


Part number	Z	Teeth	PCD	ØD Outside	ØM Boss SH	ZSH	ØA Bore		Price each 1 to 5
							SH	ZSH	
SH0.8-10	-	10	8,40	10,00	10	-	5	-	20,18 € -
SH0.8-15	ZSH0.8-15	15	12,60	14,20	12	14,20	5	3	21,55 € 10,79 €
SH0.8-16	ZSH0.8-16	16	13,44	15,04	12	15,04	5	3	22,11 € 11,04 €
SH0.8-19	ZSH0.8-19	19	15,96	17,56	12	14,00	5	4	23,52 € 11,76 €
SH0.8-20	ZSH0.8-20	20	16,80	18,40	12	14,00	5	4	23,81 € 11,89 €
SH0.8-25	ZSH0.8-25	25	21,00	22,60	12	14,00	5	4	25,01 € 12,57 €
SH0.8-28	ZSH0.8-28	28	23,52	25,12	12	14,00	5	4	25,65 € 12,85 €
SH0.8-30	ZSH0.8-30	30	25,20	26,80	16	16,00	6	5	25,93 € 12,98 €
SH0.8-35	ZSH0.8-35	35	29,40	31,00	16	16,00	6	5	26,33 € 14,52 €
SH0.8-40	ZSH0.8-40	40	33,60	35,20	16	16,00	6	5	26,60 € 14,69 €
SH0.8-45	ZSH0.8-45	45	37,80	39,40	16	16,00	6	5	26,87 € 14,87 €
SH0.8-50	ZSH0.8-50	50	42,00	43,60	16	16,00	6	5	27,30 € 17,13 €
SH0.8-55	ZSH0.8-55	55	46,20	47,80	16	18,00	6	6	27,99 € 17,62 €
SH0.8-60	ZSH0.8-60	60	50,40	52,00	16	18,00	8	6	28,46 € 21,51 €
SH0.8-66	ZSH0.8-66	66	55,44	57,04	16	18,00	8	6	29,17 € 21,97 €
SH0.8-70	ZSH0.8-70	70	58,80	60,40	16	18,00	8	6	29,42 € 25,20 €
SH0.8-75	ZSH0.8-75	75	63,00	64,60	16	18,00	8	6	29,94 € 25,65 €
SH0.8-80	ZSH0.8-80	80	67,20	68,80	16	18,00	8	6	31,44 € 26,92 €
SH0.8-90	ZSH0.8-90	90	75,60	77,20	20	22,00	8	6	33,16 € 30,05 €
SH0.8-100	ZSH0.8-100	100	84,00	85,60	20	22,00	8	8	36,89 € 33,52 €
SH0.8-120	ZSH0.8-120	120	100,80	102,40	20	30,00	10	10	48,72 € 54,09 €
SH0.8-140	ZSH0.8-140	140	117,60	119,20	20	30,00	10	10	63,81 € 67,79 €
SH0.8-150	-	150	126,00	127,60	30	-	12	-	73,76 € -

Gears available up to this size

SH0.8-164	ZSH0.8-164	164	Dimensions: contact us		On request	On request
-----------	------------	-----	------------------------	--	------------	------------

Dimensions in mm

Our other products

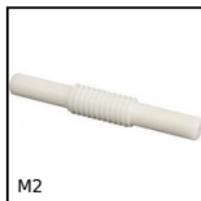

M2

Worm , Machined plastic (delrin)



RHTtcss

High Temperature Castor, up to 200kg



CHT

Asynchronous AC Motor, 0.18 to 0.55kW



EHD16

Internal epicyclic servo reducers, from 210 to 380 Nm




CRLHR

Female eye bolt high resistance, strenght alloy steel



ACLLPP

Latch for aluminium profile, Spring operated latch

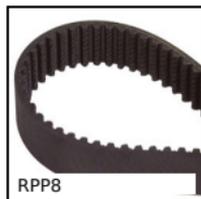

RPP8

RPP heavy duty timing belt, RPP8



WJUM10

Drylin® W bearing block, Slide



SH1

Parallel axis helical gear, Machined plastic (delrin)



PTA100ssEB

Articulated foot with sheet metal base Ø100, 15000N



UCP

Cast iron pillow block bearing, Cast iron



RAG-12-M8

Roller guide accessory, Anchoring system

Complementary products



SH0

Parallel axis helical gear, Steel 20NCD2