


Steel or **machined plastic**

## Module 1.25

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

### Info.

**Important:** a right handed gear only meshes with a left handed gear.

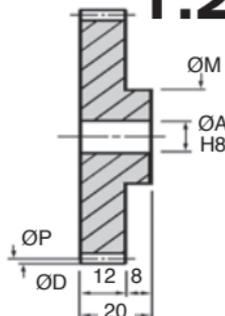

### Torque and power indication

For 50 teeth at 1000 rpm

	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	delrin
Nm	<b>6.61</b>	43.45	3.31	1.5
kW	<b>0.69</b>	4.55	0.34	-

### Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

### Plastic DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number		Z	ØP	ØD	ØM Boss	ØA Bore	Price each 1 to 5			
Steel	Plastic	Teeth	PCD	Outside	SH	ZSH	SH	ZSH		
SH1.25-10	-	10	13,13	15,63	12	-	6	23,16 €	-	
SH1.25-15	ZSH1.25-15	15	19,69	22,19	12	15	6	25,19 €	12,65 €	
SH1.25-18	ZSH1.25-18	18	23,63	26,13	15	16	8	27,39 €	13,75 €	
SH1.25-20	ZSH1.25-20	20	26,25	28,75	15	16	8	28,85 €	14,45 €	
SH1.25-21	ZSH1.25-21	21	27,56	30,06	15	18	8	29,23 €	16,13 €	
SH1.25-25	ZSH1.25-25	25	32,81	35,31	15	18	8	6 30,97 €	17,05 €	
SH1.25-30	ZSH1.25-30	30	39,38	41,88	25	18	8	6 35,49 €	19,64 €	
SH1.25-35	ZSH1.25-35	35	45,94	48,44	25	18	8	6 39,07 €	24,56 €	
SH1.25-37	ZSH1.25-37	37	45,56	51,06	25	18	8	6 39,95 €	30,14 €	
SH1.25-40	ZSH1.25-40	40	52,50	55,00	30	22	10	8 41,24 €	31,19 €	
SH1.25-45	ZSH1.25-45	45	59,06	61,56	30	22	10	8 42,11 €	36,10 €	
SH1.25-50	ZSH1.25-50	50	65,63	68,13	30	22	10	8 43,99 €	37,68 €	
SH1.25-55	ZSH1.25-55	55	72,19	74,69	30	26	10	10 45,86 €	39,30 €	
SH1.25-60	ZSH1.25-60	60	78,75	81,25	30	26	10	10 53,00 €	48,09 €	
SH1.25-65	ZSH1.25-65	65	85,31	87,81	30	26	10	10 56,22 €	51,04 €	
SH1.25-70	ZSH1.25-70	70	91,88	94,38	30	26	10	10 59,29 €	59,81 €	
SH1.25-76	ZSH1.25-76	76	99,75	102,25	30	30	10	10 61,30 €	67,94 €	
SH1.25-80	ZSH1.25-80	80	105,00	107,50	30	30	10	10 67,72 €	75,24 €	
SH1.25-88	ZSH1.25-88	88	115,50	118,00	30	30	10	10 75,02 €	83,25 €	
SH1.25-90	ZSH1.25-90	90	118,13	120,63	40	30	12	12 75,69 €	91,79 €	
SH1.25-96	ZSH1.25-96	96	126,00	128,50	30	30	10	12 87,02 €	104,86 €	
SH1.25-100	ZSH1.25-100	100	131,25	133,75	40	30	12	12 88,46 €	120,39 €	
SH1.25-120	-	120	157,50	160,00	50	-	15	-	104,74 €	-
SH1.25-130	-	130	170,63	173,13	50	-	15	-	116,73 €	-

**Gears available up to this size**

SH1.25-135	ZSH1.25-135	135	Dimensions: contact us				On request	On request
------------	-------------	-----	------------------------	--	--	--	------------	------------

Dimensions in mm

## Our other products



J64

Spur gear coaxial gearbox, from 0.57 to 2.25 Nm - In-line



PML

Solid foot mount for heavy loads, Ø 100, 120 or 150



IN1

Internal gear, Machined plastic (delrin)



CHAR16046

Spring hinge, screwed



R203

Die spring ISO10243, Light



RPP

Connecting plate for RPP type timing belts, RPP14



CHINV

Invisible hinge, Invisible - 90° opening



PRT

Rotary table iglidur®, Iglidur®, aluminium and stainless steel



AT5M AT10M

AT type timing belt per metre, AT5 Steel



CHTRP

Single and dual output gearboxes, Up



BPPEBLU

Ball transfer unit in blue certified plastic,



MEP

Revolving handle for handwheel, Fixed

## Complementary products



SH1

Parallel axis helical gear, Machined plastic (delrin)