



Steel or **machined plastic**

## Module 1.25

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

### Info.

**Important:** a right handed gear only meshes with a left handed gear.

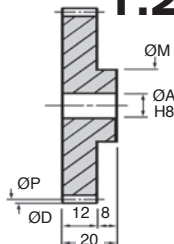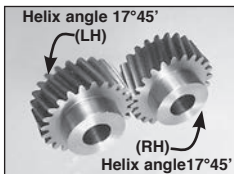

### Torque and power indication

For 50 teeth at 1000 rpm

	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	delrin
Nm	<b>6.61</b>	43.45	3.31	1.5
kW	<b>0.69</b>	4.55	0.34	-

### Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

### Plastic DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number		Z	ØP	ØD	ØM Boss	ØA Bore	Price each 1 to 5	
Steel	Plastic	Teeth	PCD	Outside	SH	ZSH	SH	ZSH
SH1.25-10	-	10	13,13	15,63	12	-	6	23,16 €
SH1.25-15	ZSH1.25-15	15	19,69	22,19	12	15	6	25,19 €
SH1.25-18	ZSH1.25-18	18	23,63	26,13	15	16	8	27,39 €
SH1.25-20	ZSH1.25-20	20	26,25	28,75	15	16	8	28,85 €
SH1.25-21	ZSH1.25-21	21	27,56	30,06	15	18	8	29,23 €
SH1.25-25	ZSH1.25-25	25	32,81	35,31	15	18	8	30,97 €
SH1.25-30	ZSH1.25-30	30	39,38	41,88	25	18	8	35,49 €
SH1.25-35	ZSH1.25-35	35	45,94	48,44	25	18	8	39,07 €
SH1.25-37	ZSH1.25-37	37	45,56	51,06	25	18	8	39,95 €
SH1.25-40	ZSH1.25-40	40	52,50	55,00	30	22	10	41,24 €
SH1.25-45	ZSH1.25-45	45	59,06	61,56	30	22	10	42,11 €
SH1.25-50	ZSH1.25-50	50	65,63	68,13	30	22	10	43,99 €
SH1.25-55	ZSH1.25-55	55	72,19	74,69	30	26	10	45,86 €
SH1.25-60	ZSH1.25-60	60	78,75	81,25	30	26	10	53,00 €
SH1.25-65	ZSH1.25-65	65	85,31	87,81	30	26	10	56,22 €
SH1.25-70	ZSH1.25-70	70	91,88	94,38	30	26	10	59,29 €
SH1.25-76	ZSH1.25-76	76	99,75	102,25	30	30	10	61,30 €
SH1.25-80	ZSH1.25-80	80	105,00	107,50	30	30	10	67,72 €
SH1.25-88	ZSH1.25-88	88	115,50	118,00	30	30	10	75,02 €
SH1.25-90	ZSH1.25-90	90	118,13	120,63	40	30	12	75,69 €
SH1.25-96	ZSH1.25-96	96	126,00	128,50	30	30	10	87,02 €
SH1.25-100	ZSH1.25-100	100	131,25	133,75	40	30	12	88,46 €
SH1.25-120	-	120	157,50	160,00	50	-	15	104,74 €
SH1.25-130	-	130	170,63	173,13	50	-	15	116,73 €

**Gears available up to this size**

SH1.25-135	ZSH1.25-135	135	Dimensions: contact us		On request	On request
------------	-------------	-----	------------------------	--	------------	------------

Dimensions in mm

## Our other products




TS01\_TW01

Drylin® T linear slide,  
up to 7000 N



BFDdII

Locking pin for  
bushes, Nickel-plated  
steel

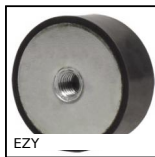

EZY

Cylindrical stop, Steel



PW\_PWG25

Worm - precision  
range, Steel



LRM

Trapezoidal bronze  
nut, Bronze - 1 thread



BC3

Panamech, Multi-  
Beam stainless steel,  
Stainless steel - with  
clampin...



BABTV

Ball lock pins lockable  
, Stainless steel




AT5M AT10M

AT type timing belt  
per metre, AT5 Steel  
cored polyurethane



PSG25S

 Spur gear - precision  
range, Stainless steel  
316



TBV

Manual lifting tables,  
20kg



COA-COG

Surface mounting  
plate, Surface  
mounting plate for



PTKss

Foot for the food  
industry, Stainless  
steel - 3-A standard

## Complementary products



SH1

Parallel axis helical  
gear, Steel 20NCD2