



Steel or **machined plastic**

Module 2.0

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

Info.

important: a right handed gear only meshes with a left handed gear.

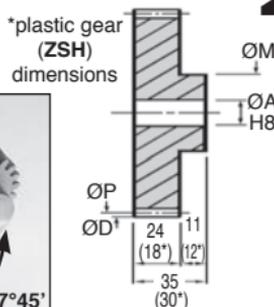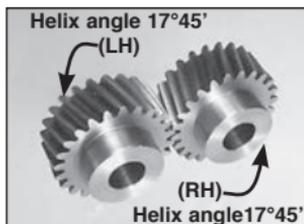

Torque and power indication

For 50 teeth at 1000 rpm

	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	delrin
Nm	33.89	134.0	16.94	8.0
kW	3.56	14.0	1.78	-

Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Plastic DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number		Z	ØP	ØD	ØM Boss	ØA Bore	Price each 1 to 5		
Steel	Plastic	Teeth	PCD	Outside	SH	ZSH	SH	ZSH	
SH2-10	ZSH2-10	10	21,00	25,00	25	24	12	10	30,17 € 15,12 €
SH2-15	ZSH2-15	15	31,50	35,50	25	25	15	12	35,59 € 19,69 €
SH2-18	ZSH2-18	18	37,80	41,80	30	30	15	12	39,17 € 21,70 €
SH2-20	ZSH2-20	20	42,00	46,00	30	30	15	12	40,98 € 25,81 €
SH2-22	ZSH2-22	22	46,20	50,20	35	30	15	12	42,84 € 27,00 €
SH2-24	ZSH2-24	24	50,40	54,40	35	30	15	12	44,70 € 33,83 €
SH2-25	ZSH2-25	25	52,50	56,50	35	30	15	12	47,15 € 35,63 €
SH2-30	ZSH2-30	30	63,00	67,00	40	30	20	12	53,84 € 46,18 €
SH2-32	ZSH2-32	32	67,20	71,20	40	30	20	12	58,49 € 50,15 €
SH2-35	ZSH2-35	35	73,50	77,50	50	30	20	12	64,64 € 58,62 €
SH2-40	ZSH2-40	40	84,00	88,00	50	35	20	12	73,83 € 67,04 €
SH2-45	ZSH2-45	45	94,50	98,50	50	35	20	15	79,50 € 80,19 €
SH2-48	ZSH2-48	48	100,80	104,80	50	35	20	15	85,59 € 95,03 €
SH2-50	ZSH2-50	50	105,00	109,00	50	35	20	15	91,57 € 101,65 €
SH2-55	ZSH2-55	55	115,50	119,50	50	35	20	15	107,27 € 119,05 €
SH2-56	ZSH2-56	56	117,60	121,60	50	35	20	15	109,55 € 132,69 €
SH2-60	ZSH2-60	60	126,00	130,00	50	35	20	15	116,67 € 141,62 €
SH2-65	ZSH2-65	65	136,50	140,50	50	40	20	15	128,20 € 168,22 €
SH2-70	ZSH2-70	70	147,00	151,00	50	40	20	15	135,67 € 178,00 €
SH2-75	ZSH2-75	75	157,50	161,50	50	50	20	15	167,85 € 254,96 €
SH2-80	-	80	168,00	172,00	50	-	20	-	203,29 € -
SH2-90	-	90	189,00	193,00	50	-	20	-	242,68 € -
SH2-100	-	100	210,00	214,00	50	-	20	-	301,66 € -
SH2-110	-	110	231,00	235,00	50	-	20	-	334,36 € -
SH2-120	-	120	252,00	256,00	50	-	20	-	388,52 € -

Gears available up to this size

SH2-280	ZSH2-280	280	dimensions: contact us		On request	On request
---------	----------	-----	------------------------	--	------------	------------

Dimensions in mm

Our other products



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2




H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



ZBconique

Machined plastic bevel gear, 1:1

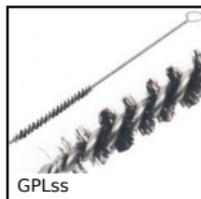

GPLss

Brush, stainless steel



PDR-RD

Mounting feet with integrated castors, Offset castor



PAP

Handle for aluminium profile, Ergonomic handle



BAC105

Storage bin, 8mm



QNUP

Single row cylindrical roller bearing, 1 fixed inner flange and 1 fr...



VDSQCB

Sliding lock adjustment system, Blocking wedge



SCH

Horizontal hook toggle clamp, Horizontal Hook



NKIB

Combined bearing with inner ring, Axial load in both directions

Complementary products



SH2

Parallel axis helical gear, Machined plastic (delrin)