



Steel or machined plastic

Module 3.0

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

Info.

Important: a right handed gear only meshes with a left handed gear.

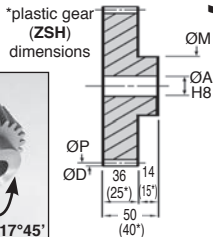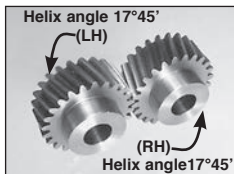

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	delrin
Nm	114.2	451.9	57.12	20.00
kW	11.9	47.4	5.98	-

Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc. List	-12%	-25%	On request	

Plastic DISCOUNTS

Qty	1+	6+	30+
Disc. List	-22%	On request	

Part number		Z	ØP	ØD	ØM	Boss	ØA	Bore	Price each 1 to 5	
Steel	Plastic	Teeth	PCD	Outside	SH	ZSH	SH	ZSH	SH	ZSH
SH3-10	ZSH3-10	10	31,50	37,50	30	36	15	12	51,36 €	28,43 €
SH3-15	ZSH3-15	15	47,25	53,25	30	40	20	15	57,14 €	35,93 €
SH3-18	ZSH3-18	18	56,70	62,70	40	40	20	15	67,51 €	51,04 €
SH3-20	ZSH3-20	20	63,00	69,00	50	40	25	15	72,20 €	61,99 €
SH3-22	ZSH3-22	22	69,30	75,30	50	40	25	15	77,28 €	66,29 €
SH3-25	ZSH3-25	25	78,75	84,75	50	40	25	15	86,87 €	78,86 €
SH3-27	ZSH3-27	27	85,05	91,05	50	50	25	20	93,99 €	85,30 €
SH3-30	ZSH3-30	30	94,50	100,50	50	50	25	20	104,22 €	105,12 €
SH3-35	ZSH3-35	35	110,25	116,25	60	50	25	20	129,47 €	143,76 €
SH3-40	ZSH3-40	40	126,00	132,00	60	50	25	20	142,95 €	173,09 €
SH3-45	ZSH3-45	45	141,75	147,75	60	60	25	20	211,22 €	256,45 €
SH3-50	ZSH3-50	50	157,50	163,50	60	60	25	20	233,84 €	352,36 €
SH3-54	ZSH3-54	54	170,10	176,10	60	70	25	20	266,62 €	404,82 €
SH3-55	ZSH3-55	55	173,25	179,25	60	70	25	20	279,30 €	409,43 €
SH3-60	ZSH3-60	60	189,00	195,00	60	70	25	20	309,59 €	470,01 €
SH3-61	-	61	192,15	198,15	60	-	25	-	318,02 €	-
SH3-62	-	62	195,30	201,30	60	-	25	-	326,37 €	-
SH3-65	-	65	204,75	210,75	60	-	25	-	344,38 €	-
SH3-70	-	70	220,50	226,50	60	-	25	-	398,34 €	-
SH3-75	-	75	236,25	242,25	60	-	25	-	442,85 €	-
SH3-80	-	80	252,00	258,00	60	-	25	-	494,14 €	-
SH3-90	-	90	283,50	289,50	60	-	25	-	650,32 €	-
SH3-92	-	92	289,80	295,80	60	-	25	-	670,58 €	-
SH3-95	-	95	299,25	305,25	60	-	25	-	743,39 €	-

Gears available up to this size

SH3-180 ZSH3-180 180

Dimensions: contact us

On request On request

Dimensions in mm

Our other products



SBF

Sealed flange bearing unit for Food Industry, cover



RPCplss

Swivel castor with double brake, Stainless steel - Polyamide



PAP

Handle for aluminium profile, Ergonomic handle



AFSE

Locking pin with interlocking safety latch, with interlocking safety...




PSG05S

Spur gear - precision range, Stainless steel 316



DHX

 Dowel pin internal thread, Extractable DIN 7979D



RLR

Roll-Ring® chain tensioner, Roll-Ring® Self-adjusting



F7-SF-SM

Multifunction display, Right angled mounting bracket




GARBAB

Lock pin for clamping, Ball lock pin




NDS20

Double cross clamp, Crossed

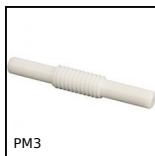

PM3

 Worm, Machined plastic (delrin)



M0

Wormwheel, Bronze

Complementary products



SH3

Parallel axis helical gear, Machined plastic (delrin)