



Steel or **machined plastic**

## Module 3.0

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

### Info.

**Important:** a right handed gear only meshes with a left handed gear.

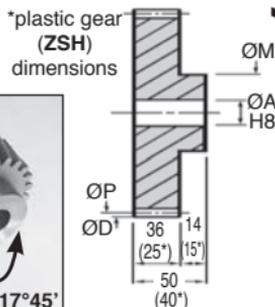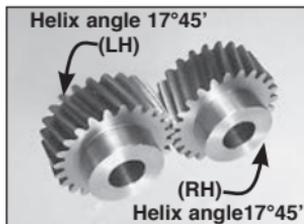

### Torque and power indication

For 50 teeth at 1000 rpm

	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	delrin
Nm	114.2	451.9	57.12	20.00
kW	11.9	47.4	5.98	-

### Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc. List	-12%	-25%	On request	

### Plastic DISCOUNTS

Qty	1+	6+	30+
Disc. List	-22%	On request	

Part number		Z	ØP	ØD	ØM	Boss	ØA	Bore	Price each 1 to 5	
Steel	Plastic	Teeth	PCD	Outside	SH	ZSH	SH	ZSH	SH	ZSH
SH3-10	ZSH3-10	10	31,50	37,50	30	36	15	12	51,36 €	28,43 €
SH3-15	ZSH3-15	15	47,25	53,25	30	40	20	15	57,14 €	35,93 €
SH3-18	ZSH3-18	18	56,70	62,70	40	40	20	15	67,51 €	51,04 €
SH3-20	ZSH3-20	20	63,00	69,00	50	40	25	15	72,20 €	61,99 €
SH3-22	ZSH3-22	22	69,30	75,30	50	40	25	15	77,28 €	66,29 €
SH3-25	ZSH3-25	25	78,75	84,75	50	40	25	15	86,87 €	78,86 €
SH3-27	ZSH3-27	27	85,05	91,05	50	50	25	20	93,99 €	85,30 €
SH3-30	ZSH3-30	30	94,50	100,50	50	50	25	20	104,22 €	105,12 €
SH3-35	ZSH3-35	35	110,25	116,25	60	50	25	20	129,47 €	143,76 €
SH3-40	ZSH3-40	40	126,00	132,00	60	50	25	20	142,95 €	173,09 €
SH3-45	ZSH3-45	45	141,75	147,75	60	60	25	20	211,22 €	256,45 €
SH3-50	ZSH3-50	50	157,50	163,50	60	60	25	20	233,84 €	352,36 €
SH3-54	ZSH3-54	54	170,10	176,10	60	70	25	20	266,62 €	404,82 €
SH3-55	ZSH3-55	55	173,25	179,25	60	70	25	20	279,30 €	409,43 €
SH3-60	ZSH3-60	60	189,00	195,00	60	70	25	20	309,59 €	470,01 €
SH3-61	-	61	192,15	198,15	60	-	25	-	318,02 €	-
SH3-62	-	62	195,30	201,30	60	-	25	-	326,37 €	-
SH3-65	-	65	204,75	210,75	60	-	25	-	344,38 €	-
SH3-70	-	70	220,50	226,50	60	-	25	-	398,34 €	-
SH3-75	-	75	236,25	242,25	60	-	25	-	442,85 €	-
SH3-80	-	80	252,00	258,00	60	-	25	-	494,14 €	-
SH3-90	-	90	283,50	289,50	60	-	25	-	650,32 €	-
SH3-92	-	92	289,80	295,80	60	-	25	-	670,58 €	-
SH3-95	-	95	299,25	305,25	60	-	25	-	743,39 €	-

**Gears available up to this size**

SH3-180 ZSH3-180 180

Dimensions: contact us

On request On request

Dimensions in mm

## Our other products



WJUM20

Drylin® W bearing block, Slide



PDD

Actuating plunger, Non-rotating detector shaft



J65

Spur gear coaxial gearbox, from 0.80 to 2.95 Nm - Inline




MHQMEP

Arm with rotating handle, Square bore shaft



UGH32

H Type Guide units, For Ø32 actuators

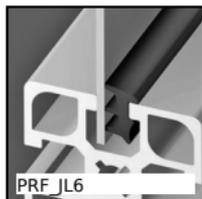

PRF-JL6

Lip seal for panel, Door seal - Ø 6mm



BS3

Panamech, Multi-Beam stainless steel, Stainless steel - with set screw



MEFC

Flanged sintered ferrous bush, Self-lubricating FP20 ferrous alloy M...



YG2

HEAVY DUTY spur gear, Steel 35NCD6



PRF-GPB

Guide for aluminium profile, Rail for 8mm wide slots



BOX-TOR-C

Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x



WSSss

Symmetrical S shaped hook stainless steel, Stainless steel

## Complementary products



SH3

Parallel axis helical gear, Steel 20NCD2