



Parallel axis helical gear



Module 4.0

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2

Steel

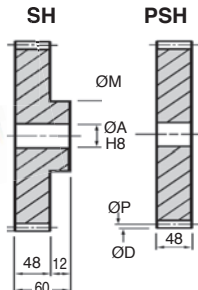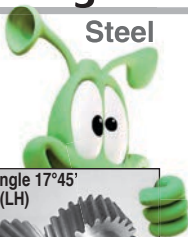

Info.

Important: a right handed gear only meshes with a left handed gear.

Torque and power indication

For 50 teeth at 1000 rpm

	20NCD2 Z10CNF18.09	20NCD2 hardened	brass
Nm	338	1340	169
kW	35	140	17

DISCOUNTS

Qty	1+	6+	20+	40+
Disc. List	-12%	-25%	On request	

Part number	Z Teeth	ØP PCD	ØD Outside	ØM Boss	ØA Bore	Price each 1 to 5	
						SH	PSH
SH4-10	10	42,00	50,00	40	20	70,55 €	On request
SH4-12	12	50,40	58,40	40	20	70,55 €	
SH4-14	14	58,80	66,80	40	20	81,48 €	
SH4-15	15	63,00	71,00	40	25	92,43 €	
SH4-18	18	75,60	83,60	50	25	113,48 €	
SH4-20	20	84,00	92,00	50	25	121,95 €	
SH4-24	24	100,80	108,80	50	25	139,88 €	
SH4-25	25	105,00	113,00	80	30	145,41 €	
SH4-28	28	117,60	125,60	80	30	164,02 €	
SH4-30	30	126,00	134,00	80	30	176,06 €	
SH4-34	34	142,80	150,80	80	30	227,06 €	
SH4-35	35	147,00	155,00	80	30	243,94 €	
SH4-36	36	151,20	159,20	80	30	260,71 €	
SH4-40	40	168,00	176,00	80	30	307,46 €	
SH4-45	45	189,00	197,00	80	30	364,30 €	
SH4-46	46	193,20	201,20	80	30	368,51 €	
SH4-50	50	210,00	218,00	80	30	393,75 €	
SH4-55	55	231,00	239,00	80	30	479,88 €	
SH4-56	56	235,20	243,20	80	30	508,12 €	
SH4-60	60	252,00	260,00	80	30	561,94 €	
SH4-65	65	273,00	281,00	80	30	744,02 €	
SH4-68	68	285,60	293,60	80	30	820,38 €	
SH4-70	70	294,00	302,00	80	30	859,46 €	
SH4-72	72	302,40	310,40	80	30	930,60 €	

Gears available up to this size

SH4-135 135

Dimensions: contact us

On request On request

Dimensions in mm

Our other products



G0
Steel spur gear, Steel
20NCD2



AC156-157
Strike for toggle latch,
25.5mm



CLQassortiment
Assorted feeler strips,
Assorted feeler strips




GG2
Ground spur gear,
Heat treated steel



WING
Manually tightened
wing nut, Steel (ANSI
B18-17)



 PSG35
Spur gear - precision
range, Stainless steel
303



RPP14
RPP heavy duty
timing belt, RPP14



GE32
Sprung toggle latch
with connecting link,
Standard



AT10courroie
AT type timing belt,
AT10 Steel cored
polyurethane



PAT85
Pressed stainless
steel articulating foot
Ø85, Ø 85



BUH77
Motor-gearbox 12V
and 24V DC, from 0.1
to 2 Nm



RFV40
Stainless steel worm
and wheel gearbox,
up to 47 Nm

Complementary products