

- **Manual operating element**
- **Materials:**  
Wheel: glass fibre reinforced polyamide  
Hub: galvanised steel


**Great value for money**

### Options

- Different bore diameters
- Keyways
- See modification info on page 54

### Uses

- All types of machines

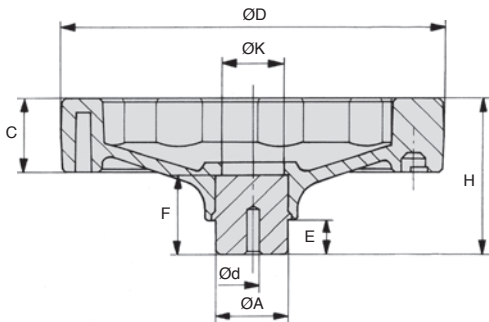

### Bore modifications



### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	Ød		ØD	H	C	ØA	E	F	ØK	Stock*	Price each 1 to 5
	Pre-bore										
SHA-100	4		100	46	20	24	12	24	18	✓	12,05 €
SHA-125	6		125	51	24	24	12	28	20	-	14,14 €
SHA-160	6		160	61	28	32	15	31	30	✓	20,93 €
SHA-200	6		200	74	32	40	15	40	35	✓	31,69 €

\*Depending on availability - Dimensions in mm

## Our other products



BCM\_TP

Modular cylindrical brush, Tampico bristles



PSG25S

Spur gear - precision range, Stainless steel 303



PSG125

Spur gear - precision range, Case hardened steel 20NCD2



T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



ALIDRP240

24V DC power supply, 10 A



BTE

Universal tension arm, For normal applications



DCA

Suction cup, 1.5 bellows, natural rubber



T10-BAR

T type tooth bar stock, T10



ETQ

Magnetic label holder for aluminium profile,



LVT

Miniature motorised actuator 4A, 4 ampers



PCLA\_T

Technopolymer clamping lever - male,



PPS

Lifting ring, Universal threaded

## Complementary products



VPPTss

Stainless steel handwheel with handle, Stainless steel 304



SHA\_PTR

Handwheel with folding handle, Polyamide