

- **Manual operating element**
- **Materials:**
Wheel: glass fibre reinforced polyamide
Hub: galvanised steel


Great value for money

Options

- Different bore diameters
- Keyways
- See modification info on page 54

Uses

- All types of machines

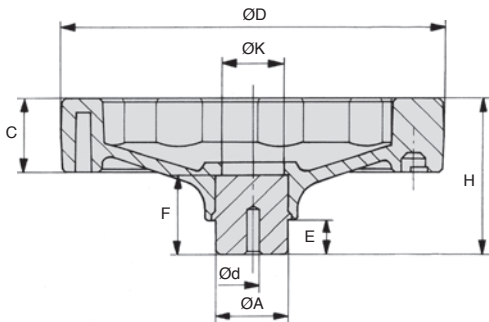

Bore modifications



DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	Ød		ØD	H	C	ØA	E	F	ØK	Stock*	Price each 1 to 5
	Pre-bore										
SHA-100	4		100	46	20	24	12	24	18	✓	12,05 €
SHA-125	6		125	51	24	24	12	28	20	-	14,14 €
SHA-160	6		160	61	28	32	15	31	30	✓	20,93 €
SHA-200	6		200	74	32	40	15	40	35	✓	31,69 €

*Depending on availability - Dimensions in mm

Our other products



AFM

Flanged polymer bush, Food grade polymer



 
LQT

Mechanical catch, Quick closing catch



MHXred

Reducing sleeve male/female, Hexagonal - stainless steel



KSM

Cylindrical steel nut, Steel - 1 thread



PITass

Locking bolt, with T handle



PSG125

Spur gear - precision range, Pre-hardened Steel 35NCD6



QNU

Single row cylindrical roller bearing, Free inner ring



BLHT50

Right angled gearbox, from 11.50 to 30 Nm




CHA35

Hinge for aluminium profile, Hinge



CHA

 Heavy duty plastic hinge, opens 180°, Heavy duty - Opens



T5courroie

T type timing belt, T5 Steel cored polyurethane



PTA100ssEB

Articulated foot with sheet metal base Ø100, Articulated foot

Complementary products



VPPTss

Stainless steel handwheel with handle, Stainless steel 304



SHA_PTR

Handwheel with folding handle, Polyamide