

- **Manual operating element**
- **Materials:**
Wheel: glass fibre reinforced polyamide
Hub: galvanised steel

Options

- Different bore diameters
- Keyways
- See modification info on page 54


Uses

- All types of machines



**Great value
for money**

Bore modifications

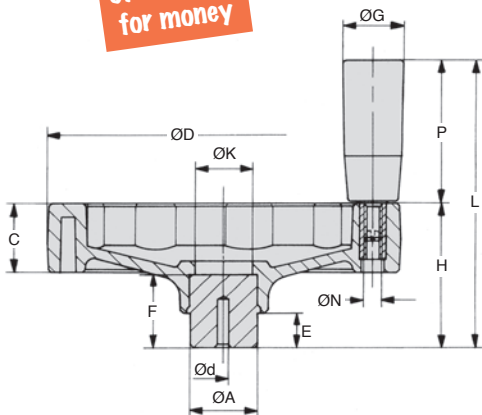


DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	Ød		H	C	ØA	E	F	ØK	L	ØG	P	ØN	Stock	Price each
	Pre-bore	ØD												1 to 5
SHA-100-PT	4	100	46	20	24	12	24	18	96	21	50	M6	✓	17,89 €
SHA-125-PT	6	125	51	24	24	12	28	20	101	21	50	M6	✓	21,63 €
SHA-160-PT	6	160	61	28	32	15	31	30	131	23	70	M8	✓	28,09 €
SHA-200-PT	6	200	74	32	40	15	40	35	164	26	90	M10	✓	40,36 €


*Depending on availability - Dimensions in mm

Our other products

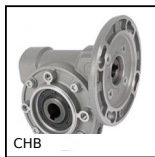

CHB

Worm and wheel gear reducer, up to 73 Nm

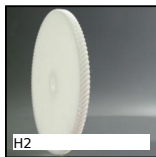

H2

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



MHQMEP

Arm with rotating handle, Square bore



EHD16

Internal epicyclic servo reducers, from 210 to 380 Nm




BAG0

Locking rings in steel, Steel



PFM

 Fixed levelling foot, Flanged plate



RPPM

RPP type belt per metre, RPP8 Steel cored polyurethane



T10_30_AL

T type timing pulley, Economy range - T10 aluminium



BTE

Universal tension arm, For standard



QNUP

Single row cylindrical roller bearing, 1 fixed



SA_SAKH

Housing for linear bearing, Closed - light



LVT

Miniatur motorised actuator 2A, 2 amperes

Complementary products



VPPTss

Stainless steel handwheel with handle, Stainless steel 304



SHA_PTR

Handwheel with folding handle, Polyamide