

Hexagonal nut **DIN 934**



SHNA SHN

Steel Class 6181 or stainless steel Class A2


- Conforms to DIN 934
- Bore chamfered at $120^\circ \pm 10^\circ$
- Exterior chamfered at 30°
- Standard pitch
- Materials:
 - Chromed steel Class 6181
 - Stainless steel 303/304 Class A2
 - Max working temperature 430°C
- Sold by the pack



Steel or
stainless steel

Options

- Also available in A4/316 stainless steel
- Fine threaded (SHN-F or N-F)

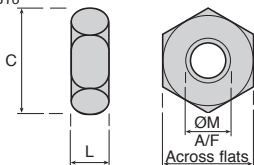

DISCOUNTS

N° packs	1+	6+	11+
Discounts	List -10%	On request	

Part number	Thread	ØM	Pitch	A/F	C	L	Qty per pack	Stock*	Price each 1 to 5
Steel class 6181									
SHNA-3/B	M3	0,50	5,5	6,01	2,4	500	-		5,27 €
SHNA-4/B	M4	0,70	7,0	7,66	3,2	500	-		2,92 €
SHNA-5/B	M5	0,80	8,0	8,79	4,0	500	-		2,99 €
SHNA-6/B	M6	1,00	10,0	11,05	5,0	500	-		6,45 €
SHNA-8/B	M8	1,25	13,0	14,38	6,5	200	-		5,51 €
SHNA-10/B	M10	1,50	17,0	18,90	8,0	100	-		6,10 €
SHNA-12/B	M12	1,75	19,0	21,10	10,0	50	-		4,48 €
SHNA-16/B	M16	2,00	24,0	26,75	13,0	25	-		4,48 €
SHNA-20/B	M20	2,50	30,0	32,95	16,0	25	-		8,52 €
Stainless steel (class A2)									
SHN-1.6/B	M1,6	0,35	3,2	3,48	1,0	500	-		87,20 €
SHN-2/B	M2	0,40	4,0	4,32	1,6	2000	✓		32,96 €
SHN-2.5/B	M2,5	0,45	5,0	5,45	2,0	500	✓		11,59 €
SHN-3/B	M3	0,50	5,5	6,01	2,4	1000	✓		13,36 €
SHN-4/B	M4	0,70	7,0	7,66	3,2	500	✓		10,79 €
SHN-5/B	M5	0,80	8,0	8,79	4,0	500	✓		14,73 €
SHN-6/B	M6	1,00	10,0	11,05	5,0	200	✓		9,14 €
SHN-8/B	M8	1,25	13,0	14,38	6,5	100	✓		10,34 €
SHN-10/B	M10	1,50	17,0	18,90	8,0	100	✓		15,71 €
SHN-12/B	M12	1,75	19,0	21,10	10,0	100	✓		25,57 €
SHN-14/B	M14	2,00	22,0	24,49	11,0	50	✓		15,44 €
SHN-16/B	M16	2,00	24,0	26,75	13,0	50	✓		37,65 €
SHN-20/B	M20	2,50	30,0	32,95	16,0	50	✓		46,55 €
SHN-24/B	M24	3,00	36,0	39,55	19,0	25	-		55,28 €

*Depending to availability - Dimensions in mm


Our other products



Spring loaded plunger with ball tip, Stainless steel body



Brush strip per meter horsehair fibres Ø0.2, Black horsehair

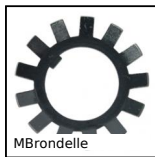

Stop washer, Stop washer MB



Adjustable friction hinges, Friction



Square decorative screwed hinges, carbon fibre reinforced



Right angled gearbox, from 1.10 to 6 Nm



Automatic chain tensioner, With wide guide



Cylindrical spacer, Brass



Plastic clamping collar, Ø10 - Ø20



Worm and wheel gear reducer, up to 980



Plastic slotted spring plunger with ball tip,



Knob for gripping, Mushroom

Complementary products



Plain washer, Steel



Socket headed screw, Steel class 12.9



Hexagonal headed bolts, Steel class 8.8



Dual-thread screw wood/metal, Steel